


Inductor

TCK-170



Order Code	TCK-170
Inductance	47 µH ±20% (100 kHz / 1 V)
Impedance (DCR)	294 mΩ max.
Rated Current	1.2 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-170



Impedance Curve

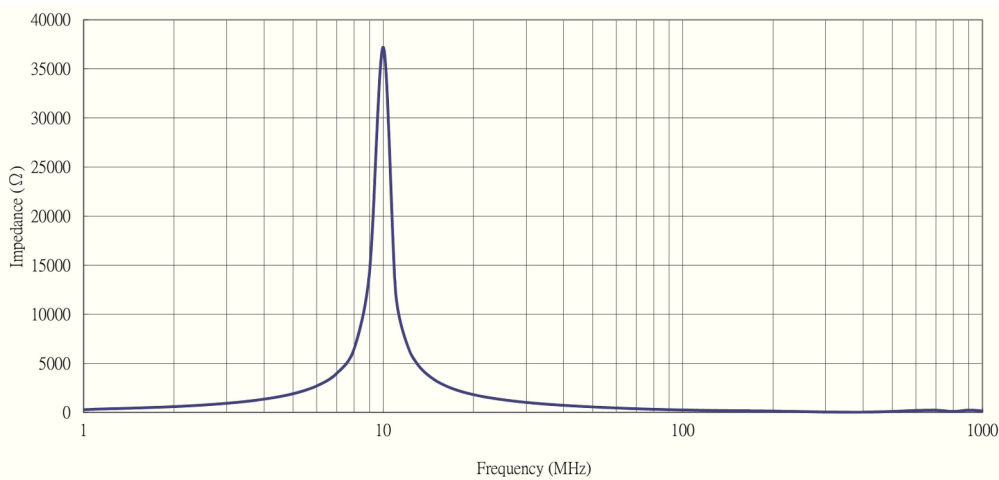

Outline Dimensions

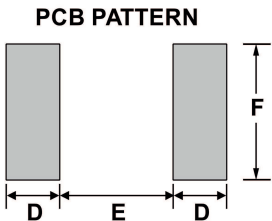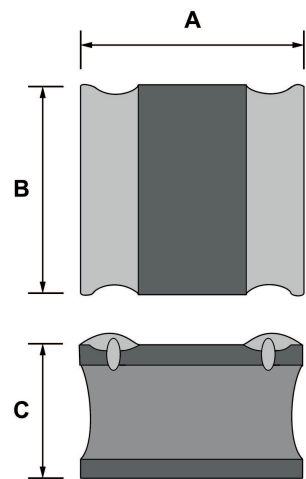

Dimensions [mm]	
A	4.9 ±0.4
B	4.9 ±0.4
C	4.2 max.
D	1.5
E	2.1
F	4.0

All specifications valid at +25°C, unless otherwise stated.