


Inductor

TCK-171


Order Code	TCK-171
Inductance	2.2 μ H $\pm$ 20% (100 kHz / 1 V)
Impedance (DCR)	17.5 m Ω max.
Rated Current	4.9 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-171



Impedance Curve

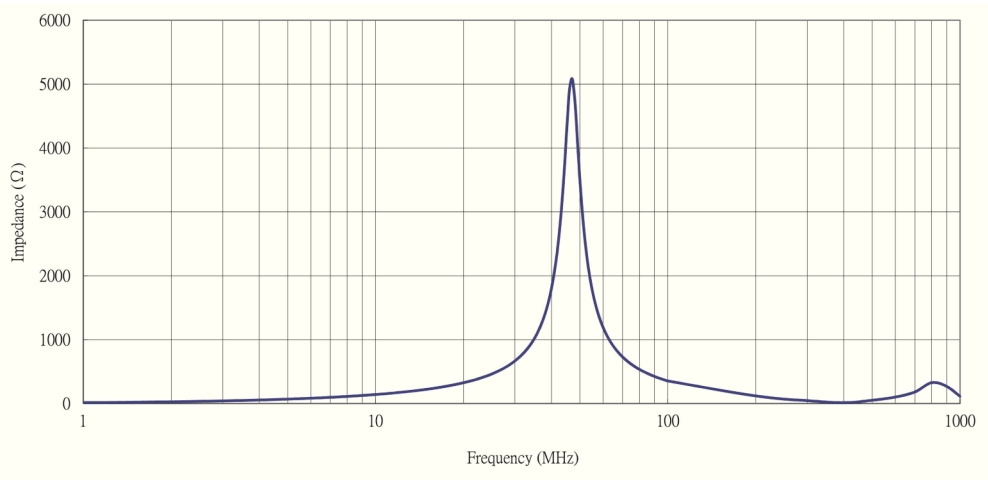

Outline Dimensions

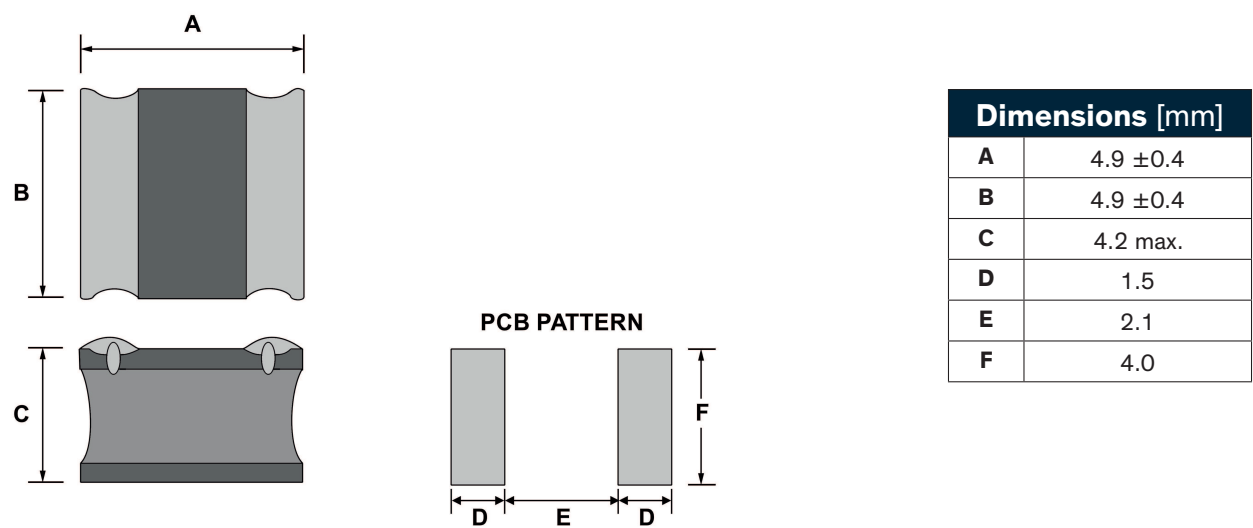

All specifications valid at +25°C, unless otherwise stated.