


Common Mode Choke

TCK-185


Order Code	TCK-185
Inductance (each winding)	$415 \mu\text{H} \pm 35\%$ (at 100 kHz / 100 mV)
Impedance (DCR)	4.7 mΩ max.
Rated Current	16 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-185



Impedance Curve

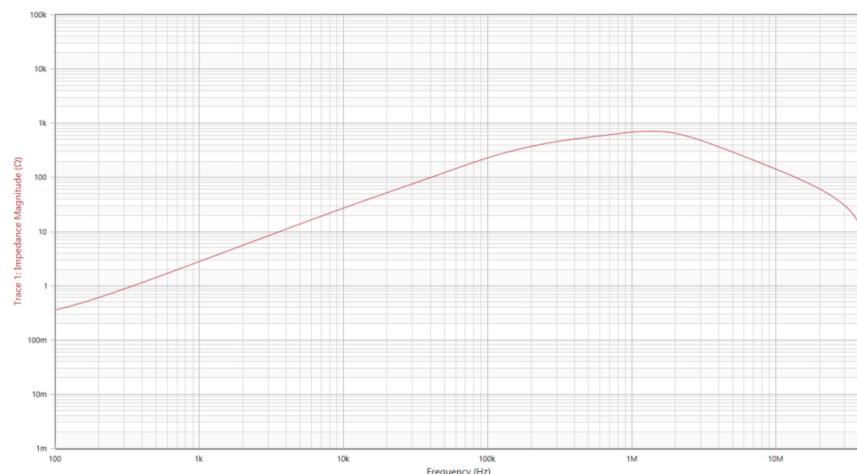

Outline Dimensions

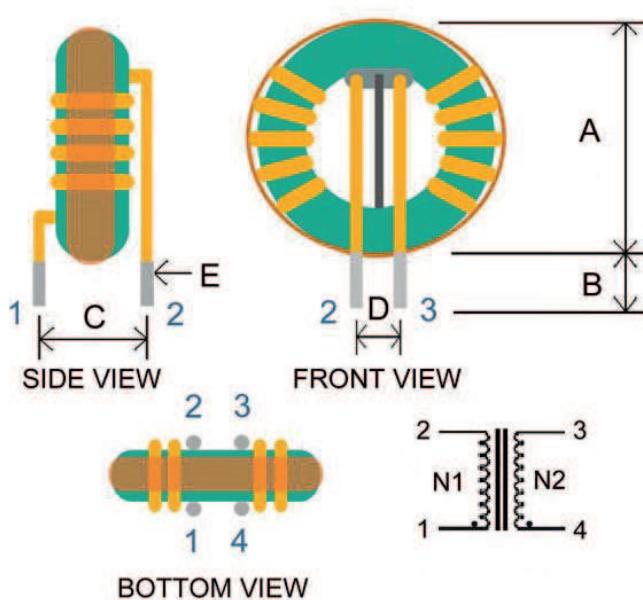

Dimensions [mm]	
A	14.45 max.
B	5.0 ±2
C	10.0 ±1
D	4.0 ±1
E	Ø1.0 ±1

All specifications valid at +25°C, unless otherwise stated.