

QUARTZ CRYSTAL MHZ

Part Number: 8301100323 | CFPX-218


AKA Number: LFX TAL100323




General Information

2.5 x 2.0 mm SMD crystal in a hermetically sealed ceramic package with a seam sealed metal lid.

Dimensions [mm]

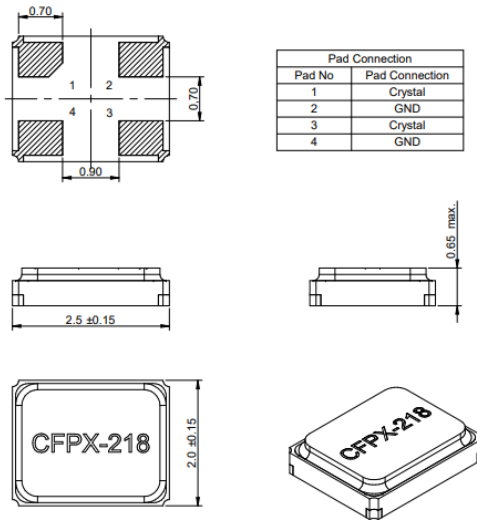

Recommended Land Pattern [mm]

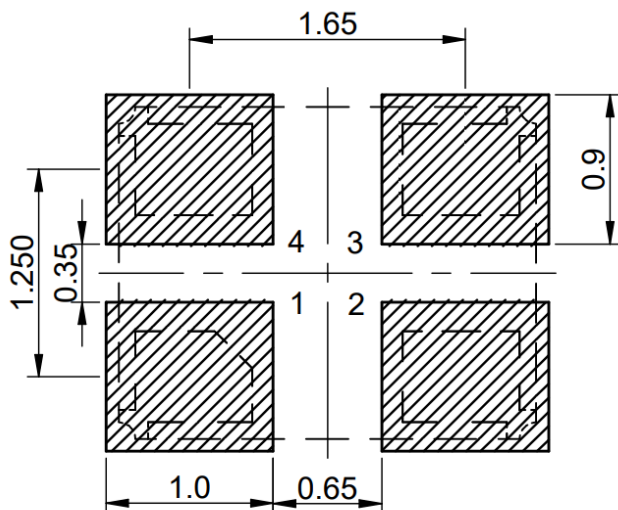

QUARTZ CRYSTAL MHZ



Part Number: **8301100323** | CFPX-218

AKA Number: LFX TAL100323

Frequency Parameters

Frequency	26.0 MHz
Frequency Tolerance	± 10 ppm @ 25 °C
Frequency Stability	± 100 ppm
Operating Temperature	-40 °C to 125 °C
Overtone Order	Fundamental
Ageing	± 3 ppm max. per year @ 25 °C

Material Parameters

Termination Finish	Au Ni
Moisture Sensitivity Level (MSL)	Not Applicable

Manufacturing Details

Reflow: 260 °C max. for 10 seconds max.

Company Address

IQD Frequency Products Ltd.
Station Road
Crewkerne
Somerset
TA18 8AR, United Kingdom

Electrical Parameters

Load Capacitance C_L	10 pF
Shunt Capacitance C_0	3 pF max.
Drive Level	100 µW max.
ESR	100 Ω max.

Environmental Parameters

Storage Temperature Range:	-55 °C to 125 °C
<ul style="list-style-type: none">Drop: 100 cm drop (3 times) onto hard wooden board.Vibration: MIL-STD-883F, Method 2007.3: 20 g (20.0 Hz ~ 2000.0 Hz), 1.52 mm amplitude, 20 minutes in each of the 3 mutually perpendicular planes (total 4 hours).	

Technical Standards

RoHS Status	2015/863/EU - Compliant
REACH Status	(EC)1907/2006 - Compliant

Packaging Details

Packaging SPQ	Tape & Reel 3000 pcs
Tape & reel in accordance with EIA-481	
Quantities below the standard reel size to be supplied on cut tape.	