

Grounding Kit Series 9076

9076.99.P038

Properties

- Easy and quick installation
- No loose piece parts
- Low contact transition resistance (1 mΩ max.)
- Grounding cable AWG 6
- Current handling capability 100 kA 8/20 μs; 25kA 10/350 μs
- Corrosion resistant



Mechanical data

Weight	0.281 kg
--------	----------

Environmental data


Operation temperature	-40 °C ... 85 °C
Storage temperature	-40 °C ... 85 °C
Ingress protection (IP Rating)	IP67
Thermal shock according	MIL-STD-202, Method 107, Cond. B
Vibration according	MIL-STD-202, Method 204, Cond. D
Moisture resistance according	MIL-STD-202, Method 106

Additional Information

Remarks	Grounding kit for LCF 3/8"
	Parallel grounding cable exit
	Grounding cable length: 830mm with screw M8

Grounding Kit Series 9076
9076.99.P038

Technical drawing

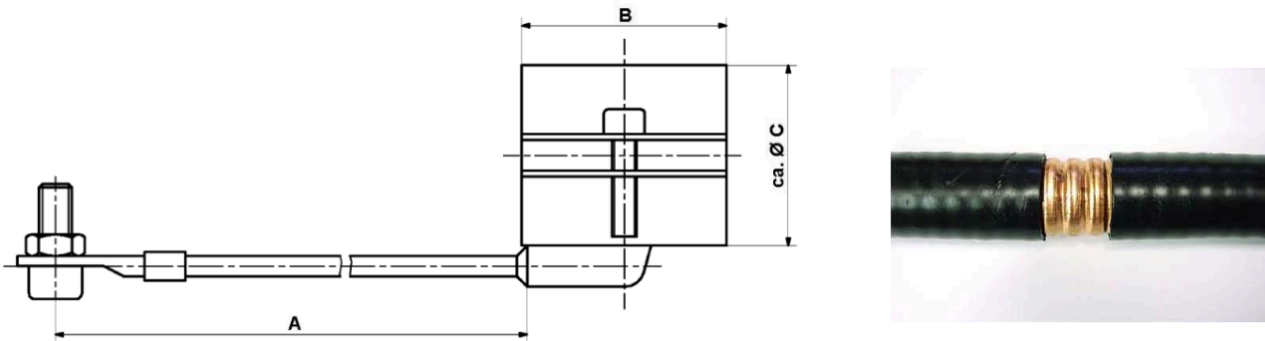

Type "P"	For cable size SUCOFEEED, Andrew, Nokia, Kabelmetal, RFS, Eupen, etc.	"A" (mm)	"B" (mm)	"C" (mm)	Stripping length (mm)	Grounding screw	Weight (g)
9076.99.P012	1/2"	840	50	32	26	M8	310
9076.99.P013	1/2" highflex	840	50	32	26	M8	310
9076.99.P014	1/4", RG213 / 214 *	840	50	28	26	M8	285
9076.99.P038	3/8"	840	50	28	26	M8	285
9076.99.P078	7/8" / 7/8" highflex	840	50	44	26	M8	335
9076.99.P114	1 -1/4"	840	70	59	26	M8	575
9076.99.P158	1 -5/8"	840	70	69	30	M8	590

* Including 3/8" highflex

Ordering Information Table	
Item number	Item description
23012650	9076.99.P038

HUBER+SUHNER is certified by ISO 9001, ISO 14001, ISO 45001, IATF 16949, AS/ EN 9100 and ISO/TS 22163-IRIS. Waiver: Facts and figures herein are for information only and do not represent any warranty of any kind.
DOCUMENT PIM-P54566 / Date of publication: 21.11.2025 / uncontrolled copy