


COAXIAL CONNECTOR, SK, 50 Ohm, Edge mount PCB jack (female)
92_SK-S50-0-202/111_U

Properties

- Non-magnetic
- For cryogenic applications
- Excellent return loss
- Mechanical intermateable with SMA and PC 3.5 (3.5 mm standard)
- Operating frequency up to 40 GHz

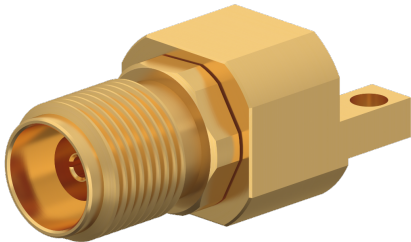

Product configuration		
Interface type	Gender	Standard
SK	jack	MIL-STD-348B
Interface and material data		
Piece parts	Material	Plating
Centre contact	Copper Beryllium Alloy	Gold Plating
Body	Copper Beryllium Alloy	Gold Plating
Insulator	PEI (Polyether-imide)	
Electrical data		
Impedance	50 Ω	
Interface frequency	40 GHz	
Electrical Data (frequency related)		
Frequency range	Return loss	VSWR
0 GHz ... 40 GHz	17 dB	1.33
Mechanical data		
Weight	0.0045 kg	
Mating cycles	500	
Environmental data		
Operation temperature	-40 °C ... 165 °C	

COAXIAL CONNECTOR, SK, 50 Ohm, Edge mount PCB jack (female)
92_SK-S50-0-202/111_U

Ordering Information Table		
Item number	Item description	Packaging type
85260944	92_SK-S50-0-202/111_UE	Single

HUBER+SUHNER is certified by ISO 9001, ISO 14001, ISO 45001, IATF 16949, AS/EN 9100 and ISO/TS 22163-IRIS. Waiver: Facts and figures herein are for information only and do not represent any warranty of any kind.
DOCUMENT PIM-P59452 / Date of publication: 24.11.2025 / uncontrolled copy