



Fastener
Solutions

7" Ladder Cable Ties Marketing Specifications

For the following part numbers:

08470-0
08472-0
08476-0
08478-0


August 1, 2018

AVERY DENNISON MARKETING SPECIFICATION

THE SUBJECT MATTER DISCLOSED HEREIN EMBODIES PROPRIETARY INFORMATION WHICH IS THE CONFIDENTIAL PROPERTY OF THE AVERY DENNISON CO. NONE OF WHICH SHALL BE COPIED, REPRODUCED, DISCLOSED TO OTHERS, PUBLISHED OR USED IN WHOLE OR IN PART, FOR ANY PURPOSE OTHER THAN THAT FOR WHICH IT IS BEING MADE AVAILABLE WITHOUT THE EXPRESS ADVANCE WRITTEN PERMISSION OF A DULY AUTHORIZED AGENT OF THE COMPANY. THIS DOCUMENT IS THE PROPERTY OF THE AVERY DENNISON CO. AND IS TO BE RETURNED TO THE COMPANY ON DEMAND.

HISTORY

REV.	DATE	DESCRIPTION
K	10.29.14	REDRAWN IN NEW FORMAT, ADDED UL INFORMATION AND LOGO

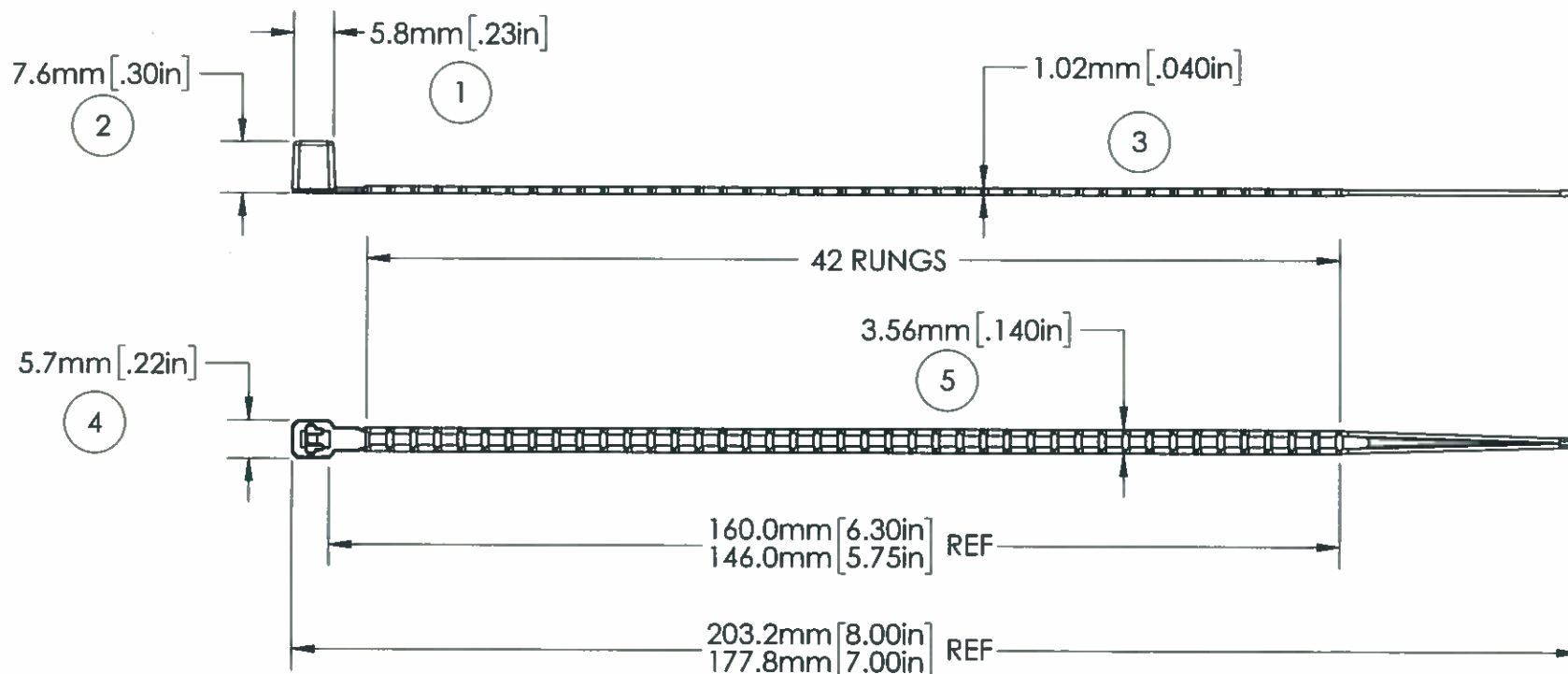

NOTE: THESE CABLE TIES ARE PLENUM RATED
AND HAVE A FLAMMABILITY RATING OF V-2



LISTED
POSITIONING DEVICE
E57800
TYPE 21

LOOP TENSILE STRENGTH:	40 LBF/180 N MIN. PER AS-23190
OPERATING TEMP RANGE:	-40°F (-40°C) TO 185°F (85°C)
MIN. INSTALLATION TEMP:	32°F (0°C)
WEIGHT:	0.51 g. / (0.01734 oz)
BUNDLE DIAMETER:	Ø 1.6mm TO Ø 44.5mm (0.06" - 1.75")
TOOL:	12001-0 - HAND TOOL 12500-0 - PNEUMATIC TOOL
PACKAGING:	1000/BAG, 5000/CASE

APPROVALS:

ENG. APPR. *ml of 7/26/2017*
Q.A. APPR. *Boyer 7/26/2017*

SPECIFIED TOLERANCES ARE:

.XX ± .03 INCHES .X ± .7 mm
.XXX ± .010 INCHES .XX ± .25 mm
ANGULAR: ± 2°

MATERIAL

NYLON 6/6

COLOR

NATURAL



AVERY DENNISON

FASTENER DIVISION
FITCHBURG, MA 01420 U.S.A.
TEL. 1-800-725-5913
FAX. 978-353-8157

DESCRIPTION

7" CABLE TIE, LADDER

STOCK NO.

08470-0

REV.


K

AVERY DENNISON MARKETING SPECIFICATION

THE SUBJECT MATTER DISCLOSED HEREIN EMBODIES PROPRIETARY INFORMATION WHICH IS THE CONFIDENTIAL PROPERTY OF THE AVERY DENNISON CO. NONE OF WHICH SHALL BE COPIED, REPRODUCED, DISCLOSED TO OTHERS, PUBLISHED OR USED IN WHOLE OR IN PART, FOR ANY PURPOSE OTHER THAN THAT FOR WHICH IT IS BEING MADE AVAILABLE WITHOUT THE EXPRESS ADVANCE WRITTEN PERMISSION OF A DULY AUTHORIZED AGENT OF THE COMPANY. THIS DOCUMENT IS THE PROPERTY OF THE AVERY DENNISON CO. AND IS TO BE RETURNED TO THE COMPANY ON DEMAND.

HISTORY

REV.	DATE	DESCRIPTION
M	10.29.14	REDRAWN IN NEW FORMAT, ADDED UL INFORMATION AND LOGO
N	07.21.16	UPDATED DIM 3, CHG FROM 1.15mm/.64mm TO 1.02mm

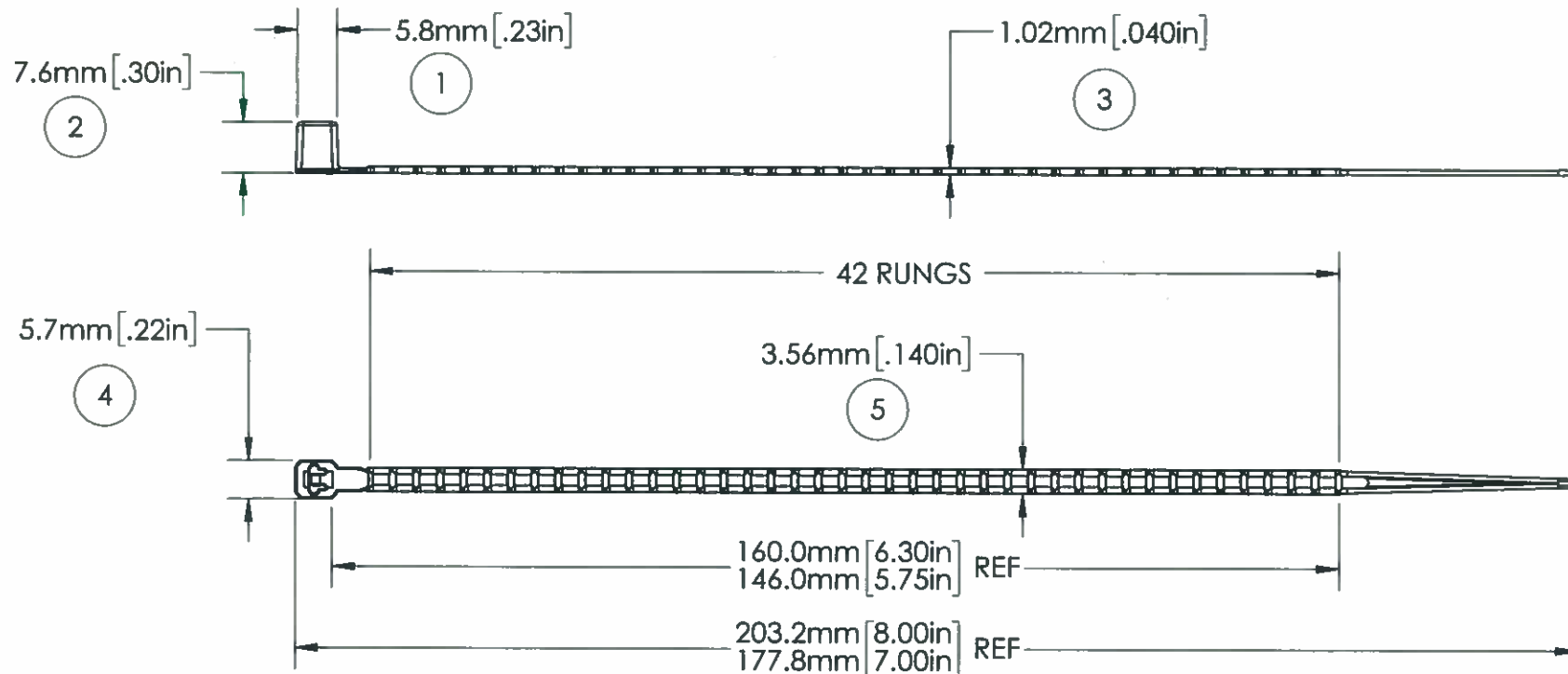

NOTE: THESE CABLE TIES ARE PLENUM RATED
AND HAVE A FLAMMABILITY RATING OF V-2



LOOP TENSILE STRENGTH:	40 LBF/180 N MIN. PER AS-23190
OPERATING TEMP RANGE:	-40°F (-40°C) TO 221°F (105°C)
MIN. INSTALLATION TEMP:	32°F (0°C)
WEIGHT:	0.51 g. / (0.01734 oz)
BUNDLE DIAMETER:	Ø 1.6mm TO Ø 44.5mm(0.06" - 1.75")
TOOL:	12001-0 - HAND TOOL 12500-0 - PNEUMATIC TOOL
PACKAGING:	1000/BAG, 5000/CASE

APPROVALS:

ENG. APPR. *[Signature]* 7/26/2017
Q.A. APPR. *[Signature]* 7/26/2017

SPECIFIED TOLERANCES ARE:

.XX ± .03 INCHES .X ± .7 mm
.XXX ± .010 INCHES .XX ± .25 mm
ANGULAR: ± 2°

MATERIAL
NYLON 6/6 HEAT STABILIZED
COLOR
BLACK



FASTENER DIVISION
FITCHBURG, MA 01420 U.S.A.
TEL: 1-800-225-5913
FAX: 978-353-8157

DESCRIPTION
7" CABLE TIE, LADDER

STOCK NO. **08472-0**


REV. **N**

AVERY DENNISON MARKETING SPECIFICATION

THE SUBJECT MATTER DISCLOSED HEREIN EMBODIES PROPRIETARY INFORMATION WHICH IS THE CONFIDENTIAL PROPERTY OF THE AVERY DENNISON CO. NONE OF WHICH SHALL BE COPIED, REPRODUCED, DISCLOSED TO OTHERS, PUBLISHED OR USED IN WHOLE OR IN PART, FOR ANY PURPOSE OTHER THAN THAT FOR WHICH IT IS BEING MADE AVAILABLE WITHOUT THE EXPRESS ADVANCE WRITTEN PERMISSION OF A DULY AUTHORIZED AGENT OF THE COMPANY. THIS DOCUMENT IS THE PROPERTY OF THE AVERY DENNISON CO. AND IS TO BE RETURNED TO THE COMPANY ON DEMAND.

HISTORY

REV.	DATE	DESCRIPTION
C	10.29.14	REDRAWN IN NEW FORMAT, ADDED UL INFORMATION AND LOGO

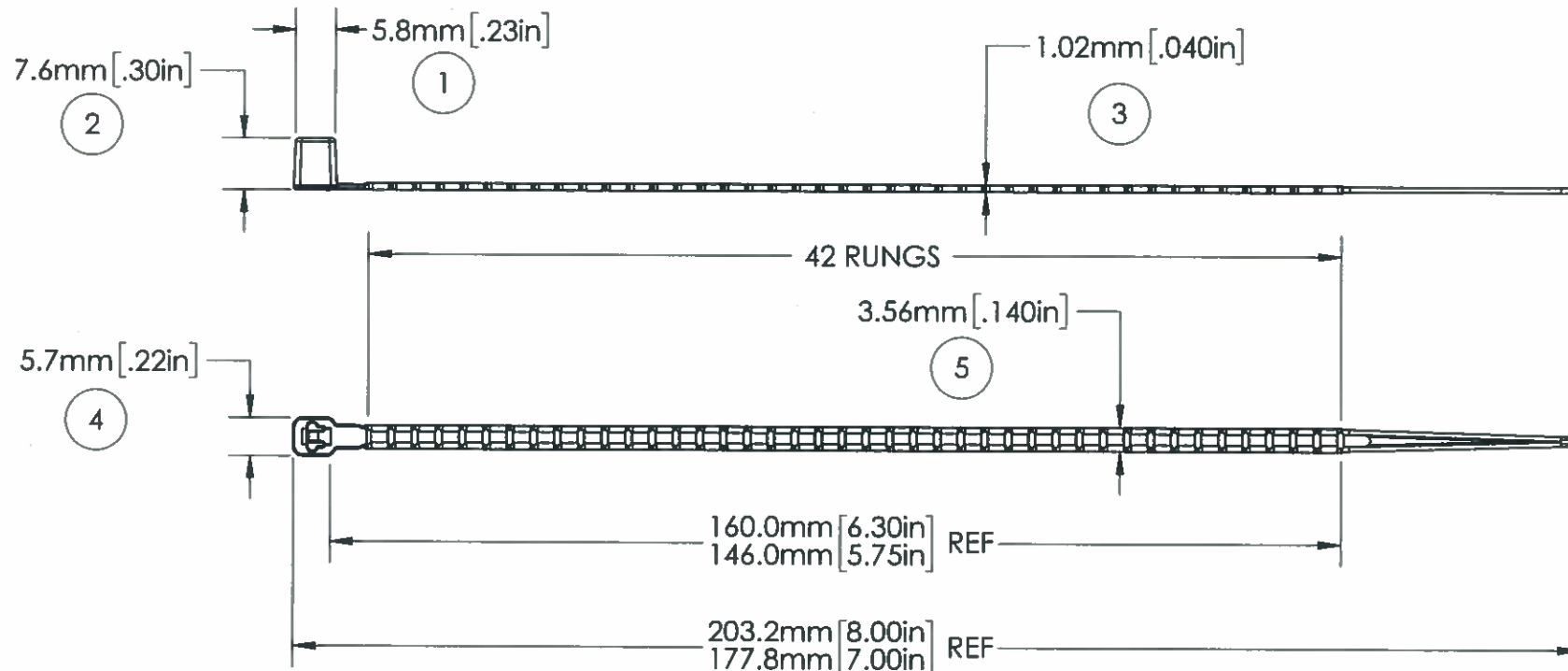

NOTE: THESE CABLE TIES ARE PLENUM RATED
AND HAVE A FLAMMABILITY RATING OF V-2



LISTED
POSITIONING DEVICE
E57800
TYPE 21


LOOP TENSILE STRENGTH:		40 LBF/180 N MIN. PER AS-23190		APPROVALS:		ENG. APPR. <i>Will d</i> 7/26/2017		 AVERY DENNISON FASTENER DIVISION FRITCHBURG, MA 01420 U.S.A. TEL: 1-800-225-5913 FAX: 978-353-8157	
OPERATING TEMP RANGE:		-40°F (-40°C) TO 185°F (85°C)				Q.A. APPR. <i>J. Boyle</i> 7/26/2017			
MIN. INSTALLATION TEMP:		32°F (0°C)		SPECIFIED TOLERANCES ARE:		MATERIAL NYLON 6/6		DESCRIPTION 7" CABLE TIE, LADDER	
WEIGHT:		0.51 g. / (0.01734 oz)							
BUNDLE DIAMETER:		Ø 1.6mm TO Ø 44.5mm(0.06" - 1.75")		.XX ± .03 INCHES .X ± .7 mm .XXX ± .010 INCHES .XX ± .25 mm		COLOR NATURAL		STOCK NO. 08476-0	
TOOL:		12001-0 - HAND TOOL 12500-0 - PNEUMATIC TOOL							
PACKAGING:		100/BAG, 5000/CASE		ANGULAR: ± 2°				REV. C	

AVERY DENNISON MARKETING SPECIFICATION

THE SUBJECT MATTER DISCLOSED HEREIN EMBODIES PROPRIETARY INFORMATION WHICH IS THE CONFIDENTIAL PROPERTY OF THE AVERY DENNISON CO. NONE OF WHICH SHALL BE COPIED, REPRODUCED, DISCLOSED TO OTHERS, PUBLISHED OR USED IN WHOLE OR IN PART, FOR ANY PURPOSE OTHER THAN THAT FOR WHICH IT IS BEING MADE AVAILABLE WITHOUT THE EXPRESS ADVANCE WRITTEN PERMISSION OF A DULY AUTHORIZED AGENT OF THE COMPANY. THIS DOCUMENT IS THE PROPERTY OF THE AVERY DENNISON CO. AND IS TO BE RETURNED TO THE COMPANY ON DEMAND.

HISTORY

REV.	DATE	DESCRIPTION
C	10.29.14	REDRAWN IN NEW FORMAT, ADDED UL INFORMATION AND LOGO
D	07.21.16	UPDATED DIM 3, CHG FROM 1.15mm/.64mm TO 1.02mm

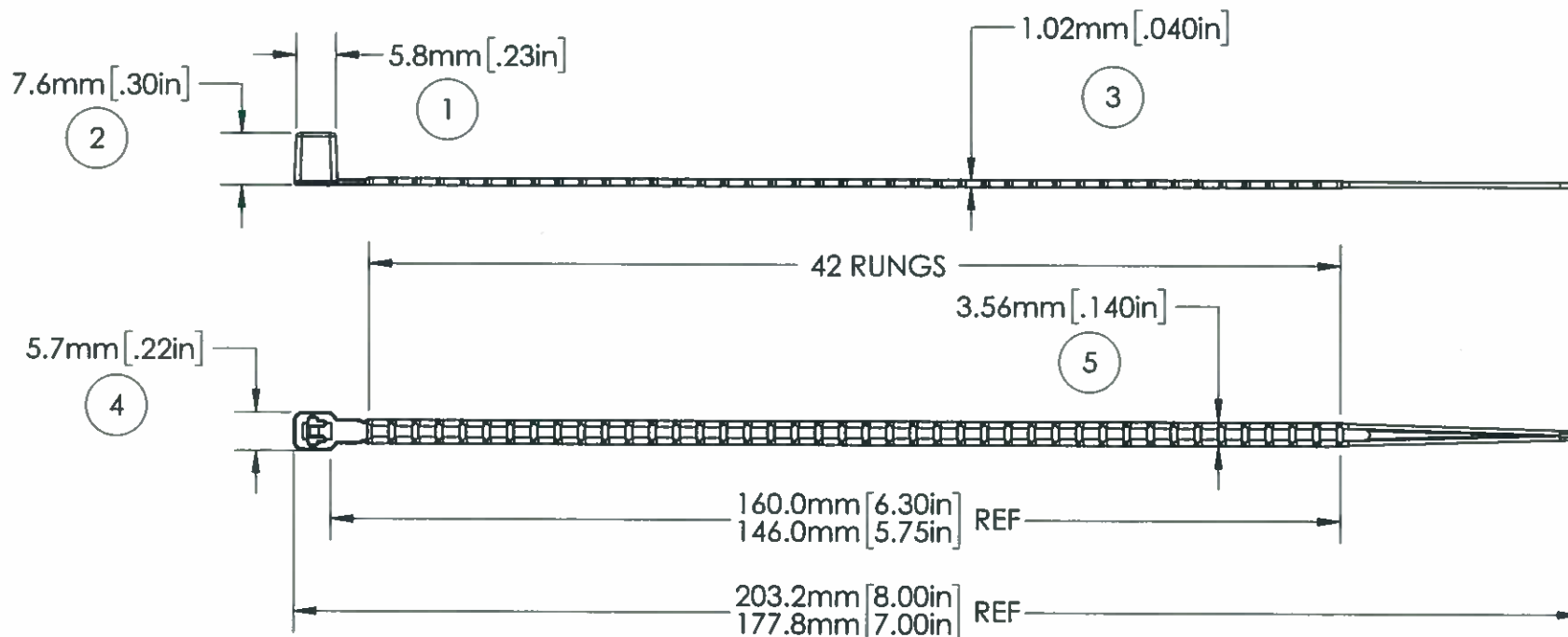

NOTE: THESE CABLE TIES ARE PLENUM RATED
 AND HAVE A FLAMMABILITY RATING OF V-2



LOOP TENSILE STRENGTH:	40 LBF/180 N MIN. PER AS-23190
OPERATING TEMP RANGE:	-40°F (-40°C) TO 221°F (105°C)
MIN. INSTALLATION TEMP:	32°F (0°C)
WEIGHT:	0.51 g. / (0.01734 oz)
BUNDLE DIAMETER:	Ø 1.6mm TO Ø 44.5mm (0.06" - 1.75")
TOOL:	12001-0 - HAND TOOL 12500-0 - PNEUMATIC TOOL
PACKAGING:	100/BAG, 5000/CASE

APPROVALS:

ENG. APPR.	<i>MLL</i> 7/26/2017
Q.A. APPR.	<i>Boyle</i> 7/26/2017

SPECIFIED TOLERANCES ARE:

.XX ± .03 INCHES	.X ± .7 mm
.XXX ± .010 INCHES	.XX ± .25 mm
ANGULAR: ± 2°	

MATERIAL

NYLON 6/6 HEAT STABILIZED

COLOR

BLACK



**AVERY
DENNISON**

FASTENER DIVISION
 FITCHBURG, MA 01420 U.S.A.
 TEL. 1-800-225-5913
 FAX. 978-353-8157

DESCRIPTION

7" CABLE TIE, LADDER

STOCK NO.

08478-0

REV.

D