
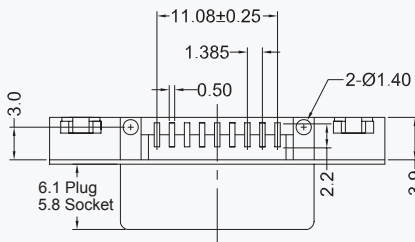
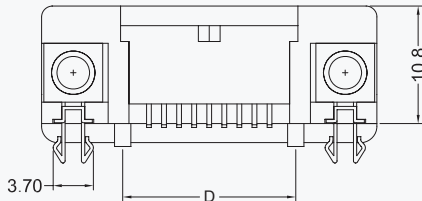


D-SUBMINIATURE CONNECTORS: K202XHT Series Right Angle Surface Mount

K202XHT Series Dimensions Dimensions in mm

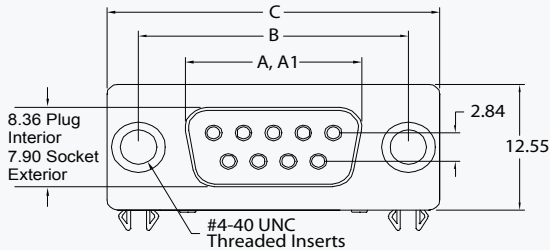

Shell Size In mm	A ±.010 ±0.25	A1 ±.010 ±0.25	B ±.005 ±0.13	C ±.015 ±0.38	D ±.005 ±0.13
9 (E)	.643 16.33	.666 16.92	.984 24.99	1.213 30.81	.626 15.90
15 (E)	.643 16.33	N/A	.984 24.99	1.213 30.81	.609 15.46
25 (B)	1.511 38.38	1.534 38.96	1.852 47.04	2.088 53.04	1.498 38.06

A = Exterior of Female Shell (S)
A1 = Interior of Male Shell (P)

2D Drawing

IGES

STEP

3D PDF

Solder Profile

CofC RoHS Compliant

CofC REACH Compliant

UL Plastic File

Certificate of Origin

Check Stock

Request a Sample

Send Us An Email

Generated Part Number

Part Number Builder

	-				
Series		Shell Size Contact	Contact Type	Mounting Option	Plating Option

Series

K202XHT - D-Subminiature Connector, Right Angle,
Ultra Short Footprint, Surface Mount, Reflow Compatible

Shell Size-Contact Option

E - 9 Contacts

B - 25 Contacts

E - 15 Contacts, High Density (Socket only)

Contact Type

P - Pin Contact (Plug)

S - Socket Contact (Receptacle)

Mounting Option

N - With Boardlocks and #4-40 UNC Threaded Inserts

NJ - With Boardlocks and **JSX-1055** Jackscrews Installed

Plating Option

Blank - Gold Flash

15 - 15µ" Gold

30 - 30µ" Gold

Contact Kycon for Tape and Reel and Other Options