

Product data sheet

Specifications

SQUARE D



NEMA Contactor, Type S,
nonreversing, Size 2, 45A, 25 HP
at 575 VAC, 3 phase, up to 100
kA, 3 pole, 480 VAC coil, open
[TAA]

8502SDO2V06

Product availability: Stock - Normally stocked in distribution facility

Main

Product Type	Contactor
Product Range	8502S
Contactor Type	Non-reversing

Complementary

NEMA Size	2
Rated Current	45 A
Number of Poles	3P
Maximum Voltage Rating	600 V AC
Phase	3 phase
Horsepower Rating	10 HP 200 V AC 15 HP 230 V AC 25 HP 460 V AC 25 HP 575 V AC
SCCR	Circuit-breaker 100 A maximum, SCCR: 100 kA at 480 V AC Fuse J 100 A maximum, SCCR: 100 kA at 600 V AC Fuse T 100 A maximum, SCCR: 100 kA at 600 V AC Fuse RK1 100 A maximum, SCCR: 100 kA at 600 V AC Fuse RK5 100 A maximum, SCCR: 100 kA at 600 V AC
Coil Voltage	480 V AC 60 Hz 440 V AC 50 Hz
Control Circuit Type	Common control circuit
Control Units	No control units
Pilot Light	No indicator
Auxiliary Contacts	Uden
Other Equipment	Fuse not supplied
Terminal Type	Screw clamp terminals
Height	5.13 in (130.30 mm)
Width	4.31 in (109.47 mm)
Depth	4.94 in (125.48 mm)

Environmental

Enclosure Type	Not rated (open device)
----------------	-------------------------

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Certifications	UL listed file E78351 CCN NLDX CSA
----------------	---------------------------------------

Ordering and shipping details

Category	US10CP121192
----------	--------------

Discount Schedule	0CP1
-------------------	------

GTIN	785901881605
------	--------------

Returnability	Yes
---------------	-----

Country of origin	MX
-------------------	----

Packing Units

Unit Type of Package 1	PCE
------------------------	-----

Nbr. of units in pkg.	1
-----------------------	---

Package 1 Height	6.90 in (17.526 cm)
------------------	---------------------

Package 1 Width	6.60 in (16.764 cm)
-----------------	---------------------

Package 1 Length	9.40 in (23.876 cm)
------------------	---------------------

Package weight(Lbs)	5.639 lb(US) (2.558 kg)
---------------------	-------------------------

Contractual warranty

Warranty	18 months
----------	-----------



Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Use Better

Materials and Substances

Packaging made with recycled cardboard	Yes
Packaging without single use plastic	Yes
EU RoHS Directive	Not compliant
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov


Use Again

Repack and remanufacture

Take-back	No
-----------	----

Technical Illustration

Dimensions

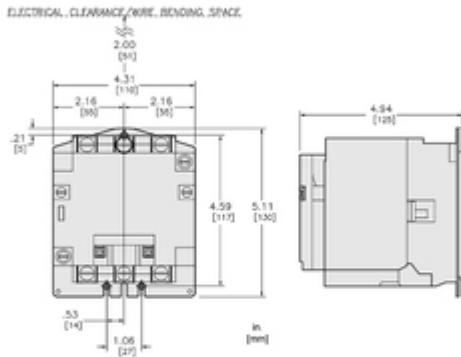

ALL DIMENSIONS ARE APPROXIMATE.
ALSO SEE TECHNICAL DRAWINGS AND DOCUMENTATION.