


# Product data sheet

Specifications

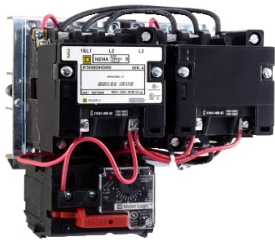

NEMA Starter, Type S, reversing, horizontal, Size 0, 18A, 5 HP at 575 VAC, up to 100 kA SCCR, 3 phase, 3 pole, Motor Logic SSOLR, 120 VAC coil, open [TAA]

8736SBO4V02H30S

Product availability: Non-Stock - Not normally stocked in distribution facility

## Main

|               |           |
|---------------|-----------|
| Product Type  | Starter   |
| Product Range | S         |
| Starter Type  | Reversing |

## Complementary

|                        |                                                                                                                                                                                                                                  |
|------------------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| NEMA Size              | 0                                                                                                                                                                                                                                |
| Rated Current          | 18 A                                                                                                                                                                                                                             |
| Number of Poles        | 3P                                                                                                                                                                                                                               |
| Mounting Orientation   | Horizontal                                                                                                                                                                                                                       |
| Wiring Mode            | 3 wires                                                                                                                                                                                                                          |
| Maximum Voltage Rating | 600 V AC                                                                                                                                                                                                                         |
| Phase                  | 3 phase                                                                                                                                                                                                                          |
| Type of Overload       | Solid state Motor Logic class 10/20                                                                                                                                                                                              |
| Horsepower Rating      | 3 HP 200 V AC<br>3 HP 230 V AC<br>5 HP 460 V AC<br>5 HP 575 V AC                                                                                                                                                                 |
| SCCR                   | Circuit-breaker 70 A maximum: 100 kA at 480 V AC<br>Fuse J 60 A maximum: 100 kA at 600 V AC<br>Fuse T 60 A maximum: 100 kA at 600 V AC<br>Fuse RK1 60 A maximum: 100 kA at 600 V AC<br>Fuse RK5 60 A maximum: 100 kA at 600 V AC |
| Coil Voltage           | 110 V AC 50 Hz<br>120 V AC 60 Hz                                                                                                                                                                                                 |
| Control Circuit Type   | Separate control circuit                                                                                                                                                                                                         |
| Control Units          | No control units                                                                                                                                                                                                                 |
| Pilot Light            | Without pilot light                                                                                                                                                                                                              |
| Auxiliary Contacts     | Uden                                                                                                                                                                                                                             |
| Terminal Type          | Screw clamp terminals                                                                                                                                                                                                            |
| Height                 | 6.91 in (175.51 mm)                                                                                                                                                                                                              |
| Width                  | 7.13 in (181.10 mm)                                                                                                                                                                                                              |
| Depth                  | 5.31 in (134.87 mm)                                                                                                                                                                                                              |

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

## Environment

|                |                         |
|----------------|-------------------------|
| Enclosure Type | Not rated (open device) |
| Certifications | UL Listed<br>CSA        |

## Ordering and shipping details

|                   |              |
|-------------------|--------------|
| Category          | US10CP121271 |
| Discount Schedule | 0CP1         |
| GTIN              | 785901703167 |
| Returnability     | Yes          |
| Country of origin | MX           |

## Packing Units

|                        |                          |
|------------------------|--------------------------|
| Unit Type of Package 1 | PCE                      |
| Nbr. of units in pkg.  | 1                        |
| Package 1 Height       | 8.30 in (21.082 cm)      |
| Package 1 Width        | 8.50 in (21.59 cm)       |
| Package 1 Length       | 12.30 in (31.242 cm)     |
| Package weight(Lbs)    | 10.139 lb(US) (4.599 kg) |

## Contractual warranty

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Use Better

|  Materials and Substances |                                                                                                                                                                                                                                                                                             |
|------------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Packaging made with recycled cardboard                                                                     | Yes                                                                                                                                                                                                                                                                                         |
| Packaging without single use plastic                                                                       | Yes                                                                                                                                                                                                                                                                                         |
| EU RoHS Directive                                                                                          | Not compliant                                                                                                                                                                                                                                                                               |
| California proposition 65                                                                                  | WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a> |

Use Again

|  Repack and remanufacture |    |
|------------------------------------------------------------------------------------------------------------|----|
| Take-back                                                                                                  | No |