


8501XTE1Y414

NEMA Control Relay, Type X, pneumatic timer attachment, one minute on delay, 10A resistive at 600 VAC, 1 NO and 1 NC, ring tongue

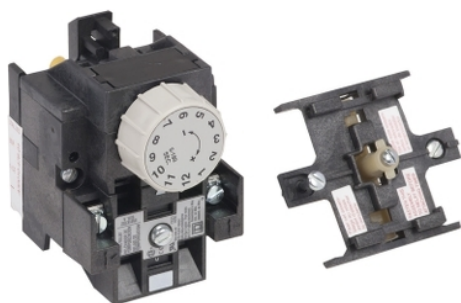

Main

Range of Product	8501X
Relay Type	Control relay
Product or Component Type	Timing relay

Complementary

Contacts Configuration	1 NO/1 NC
Time delay type	On-delay
Time range	0.2...60 s
Electrical Connection	Ring tongue
Wire Gauge	AWG 18...AWG 12 copper
Terminal Tightening Torque	Control circuit 9.03...12.04 lbf.in (1.02...1.36 N.m) screw terminals

Environment

Product Certifications	CE CSA LR60905 class 3211 02 UL recognized E78403 CCN NKCR2
------------------------	---

Ordering and shipping details

Category	21159-8501 X ACCESSORIES
Discount Schedule	CP2
GTIN	785901018551
Returnability	No
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.54 in (6.452 cm)
Package 1 Width	1.00 in (2.54 cm)
Package 1 Length	6.45 in (16.387 cm)
Package 1 Weight	6.40 oz (181.437 g)

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------