

Product data sheet

Specifications



Hand-held remote control, Harmony Pocket Remote, 4 single-step push buttons

ZART04

Product availability: Stock - Normally stocked in distribution facility

Main

Range of Product	Harmony Pocket Remote
Product or Component Type	Hand-held remote control
Device short name	ZART
Control Button Type	4 single step push-button

Complementary

Material	Push-button cover silicone rubber Enclosure ABS + PET
Function Available	Power switch
Display type	1 LED
Operating Distance	50 m
Communication network type	Wireless
Transmission frequency	2.4 GHz
Maximum sensing distance	984.3 ft (300 m) in free field
Response time	< 500 ms
Autonomy	> 100 h with alkaline batteries
Battery type	2 AAA/LR3 alkaline
Width	2.6 in (66 mm)
Height	4.5 in (114 mm)
Depth	1.5 in (37.5 mm)
Product Weight	0.298 lb(US) (0.135 kg)

Environment

Radio agreement	IC FCC
IP degree of protection	IP67
Ambient Air Temperature for Operation	-4...131 °F (-20...55 °C)
Ambient Air Temperature for Storage	-4...113 °F (-20...45 °C)
Operating altitude	0...6561.68 ft (0...2000 m)
Storage altitude	0...9842.5 ft (0...3000 m)
Relative humidity	0...95 % -4...140 °F (-20...60 °C) operating
Product Certifications	CE

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Ordering and shipping details

Category	US10CS222467
Discount Schedule	0CS2
GTIN	3606481499462
Returnability	Yes
Country of origin	CN

Packing Units

Unit Type of Package 1	PCE
Nbr. of units in pkg.	1
Package 1 Height	1.77 in (4.5 cm)
Package 1 Width	2.95 in (7.5 cm)
Package 1 Length	5.31 in (13.5 cm)
Package weight(Lbs)	6.2 oz (175.0 g)
Unit Type of Package 2	S01
Number of Units in Package 2	8
Package 2 Height	5.91 in (15.0 cm)
Package 2 Width	5.91 in (15.0 cm)
Package 2 Length	15.75 in (40.0 cm)
Package 2 Weight	3.51 lb(US) (1.59 kg)



Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint

Environmental Disclosure

[Product Environmental Profile](#)

Use Better

Materials and Substances

Packaging made with recycled cardboard No

Packaging without single use plastic No

[EU RoHS Directive](#) Pro-active compliance (Product out of EU RoHS legal scope)

SCIP Number 6e438e59-42d1-4633-bfe2-cb5ef607659b

California proposition 65 WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov


Use Again

Repack and remanufacture

Circularity Profile [End of Life Information](#)


Take-back No

WEEE Label ☒ The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

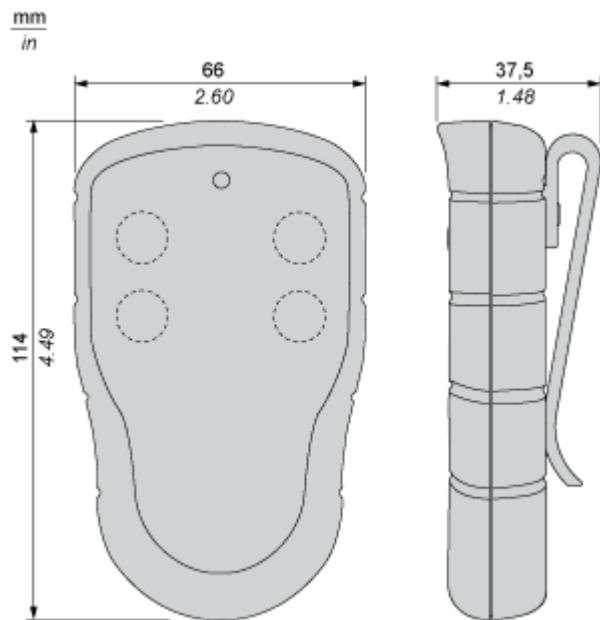Dimensions Drawings**Transmitter Dimensions**

Technical Illustration

Dimensions

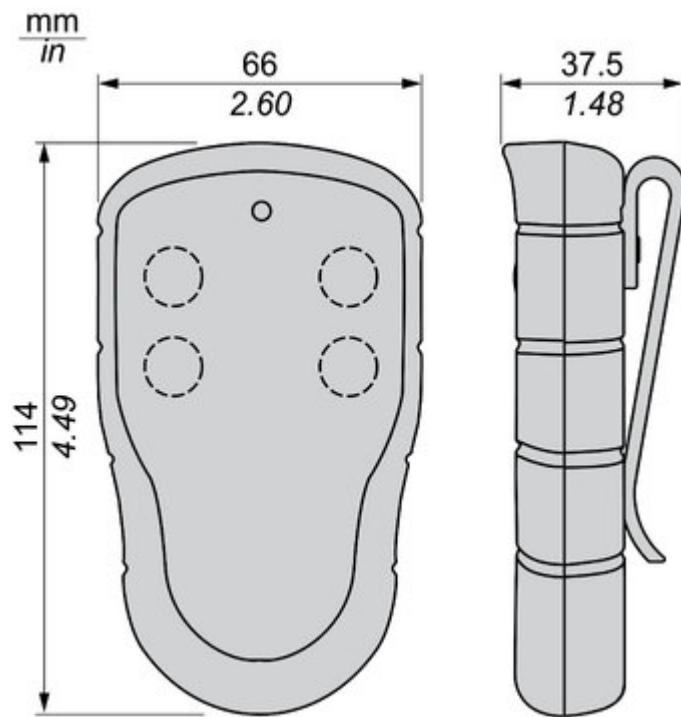

Offer Marketing Illustration

Product benefits / Features



Offer Marketing Illustration

Product benefits / Features

Technical benefits

ZAR Harmony Pocket remote

The Harmony Pocket Remote uses the worldwide free 2.4 GHz frequency to allow unrestricted operation.

Product certifications:
CE, UL
Radio certifications:
FCC, IC

Users can integrate 3, 4, 6, 8 or 10 buttons according to their needs

IP 67 for the transmitter and IP 66 for the receiver

