

# Product data sheet

Specifications



flat screen, Harmony iPC, 15inch wide display, single touch, for modular box pc

HMIDM7421

! To be discontinued

! Discontinued on: Apr 30, 2025

! To be end-of-service on: Apr 30, 2029

**Product availability: Stock - Normally stocked in distribution facility**

## Main

Range of Product	Harmony iPC
Terminal type	Touchscreen display
Product or Component Type	Flat screen

## Complementary

View angle horizontal x vertical	140 x 115°
Contrast Ratio	500:1
Touchscreen resolution	2048 x 2048
Display resolution	1024 x 768 pixels XGA
Display type	LED Colour TFT LCD
Luminance	27.9 fc (300 cd/m <sup>2</sup> )
Touch panel	Single touch analogue resistive
Function Available	Operate with water on screen
Product Compatibility	Modular Box PC
Display size	15 inch
Aspect ratio	4:3
[Us] rated supply voltage	24 V DC power supply 100...240 V AC power supply
Supply voltage limits	18...36 V
Display colour	16777216 colors
Pixel resolution	2048 x 2048
Local signalling	Status LED
Inrush current	8.9 A
Device mounting	Flush
Width	15.4 in (390.7 mm)
Height	11.4 in (290 mm)
Product Weight	9.3 lb(US) (4.2 kg)

## Environment

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

<b>Standards</b>	Class I division 2 CSA C22.2 No 213 CSA C22.2 No 142 UL 6110-2-201 Class I division 2 ANSI/ISA 12-12-01
<b>Pollution degree</b>	2
<b>Operating altitude</b>	6561.68 ft (2000 m)
<b>Product certifications</b>	EAC ATEX C-tick IEC-Ex Marine GL Bridge CE
<b>NEMA degree of protection</b>	NEMA 4X
<b>Ambient air temperature for operation</b>	32...131 °F (0...55 °C)

## Ordering and shipping details

<b>Category</b>	US10MC222574
<b>Discount Schedule</b>	0MC2
<b>GTIN</b>	3606480853661
<b>Returnability</b>	Yes
<b>Country of origin</b>	ID

## Packing Units

<b>Unit Type of Package 1</b>	PCE
<b>Number of Units in Package 1</b>	1
<b>Package 1 Height</b>	9.09 in (23.100 cm)
<b>Package 1 Width</b>	24.33 in (61.800 cm)
<b>Package 1 Length</b>	29.13 in (74.000 cm)
<b>Package 1 Weight</b>	15.366 lb(US) (6.970 kg)
<b>Unit Type of Package 2</b>	P12
<b>Number of Units in Package 2</b>	5
<b>Package 2 Height</b>	41.34 in (105.000 cm)
<b>Package 2 Width</b>	31.50 in (80.000 cm)
<b>Package 2 Length</b>	47.24 in (120.000 cm)
<b>Package 2 Weight</b>	154.324 lb(US) (70.000 kg)



Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

### Environmental footprint

Carbon footprint (kg CO2 eq, Total Life cycle)	782
Environmental Disclosure	<a href="#">Product Environmental Profile</a>

### Use Better

#### Materials and Substances

F-gas usage performance	Only air and vacuum used for insulation / breaking, no F-gas including SF6
Packaging made with recycled cardboard	Yes
Packaging without single use plastic	Yes
<a href="#">EU RoHS Directive</a>	Pro-active compliance (Product out of EU RoHS legal scope)
REACH Regulation	<a href="#">REACH Declaration</a>
California proposition 65	<b>WARNING:</b> This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="#">www.P65Warnings.ca.gov</a>


### Use Again

#### Repack and remanufacture

Circularity Profile	<a href="#">End of Life Information</a>
Take-back	No
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

## Dimensions Drawings


## Dimensions

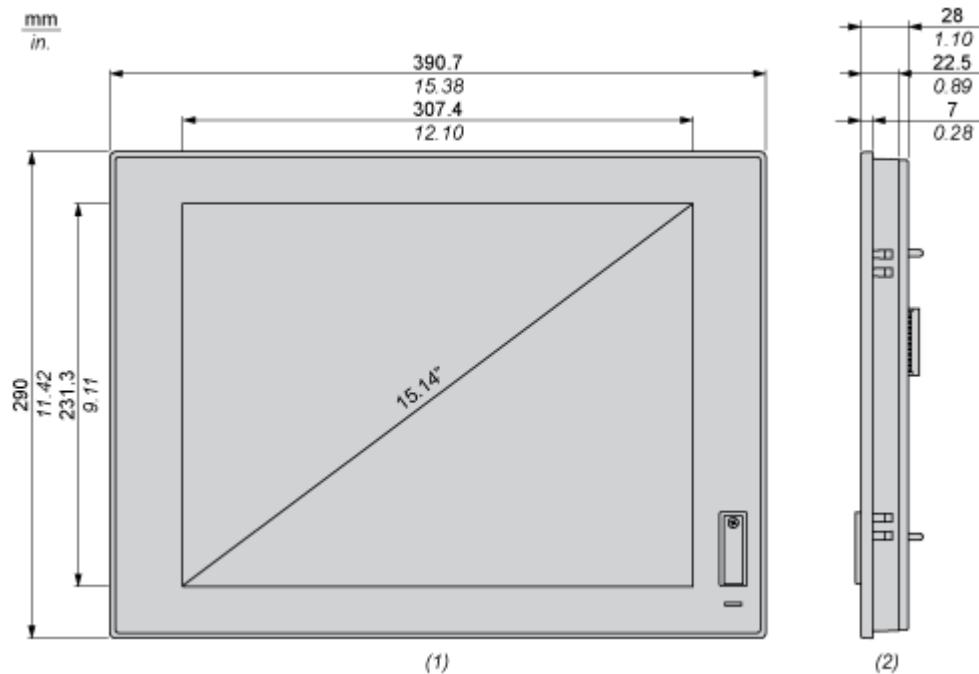

(1) Front view


(2) Right view

## Mounting and Clearance

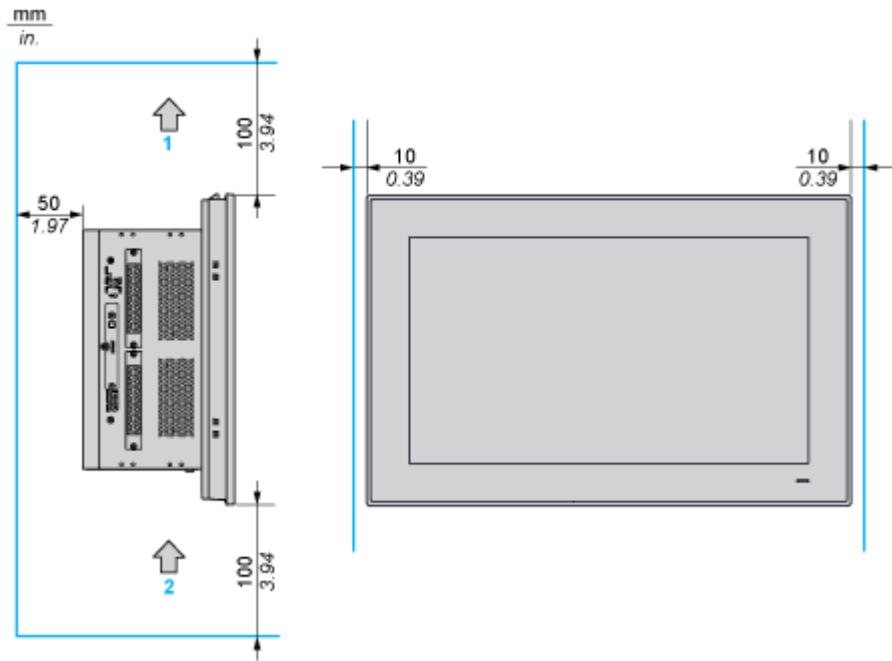
Spacing Requirements

**Mounting Orientation**

---

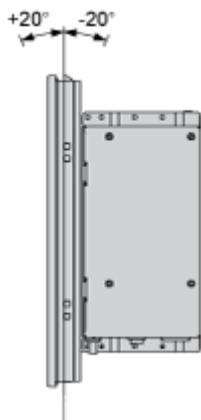

### Panel Cut Dimensions

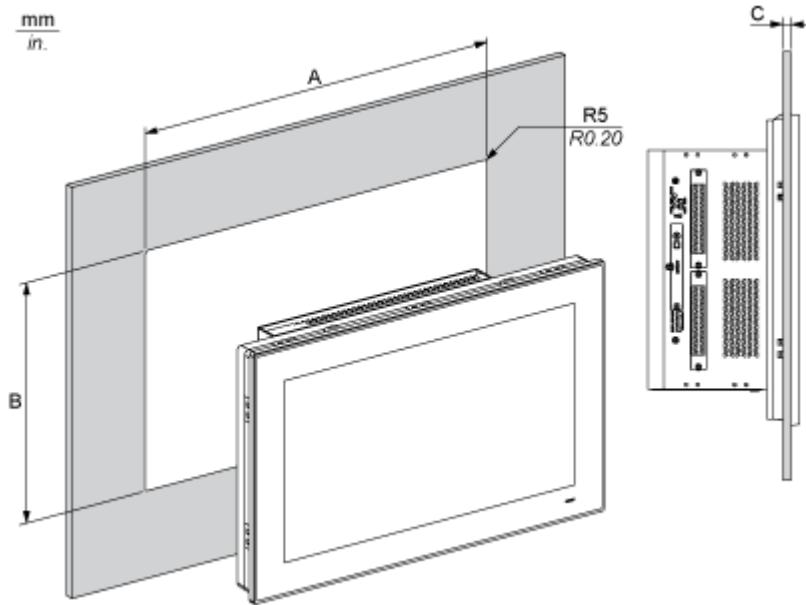

A		B		C		R	
mm	in.	mm	in.	mm	in.	mm	in.
383.5	15.09	282.5	11.12	2...6	0.08...0.23	5	0.20