

# Product data sheet

Specifications



Empty enclosure, Harmony XALK, XALD, plastic, yellow lid, for illuminated emergency stop push button 22mm, 1 cut out

XALKW01

## Main

Range of product	Harmony XALK
Product or component type	Empty control station
Device short name	XALK
Product destination	For XB5 Ø 22 mm control and signalling units
Control station application	Emergency stop function Emergency switching off function
Number of cut-out	1 cut-out
Colour of base of enclosure	Light grey (RAL 7035)
Colour of cover	Yellow (RAL 1021)
Material	Polycarbonate
Cable entry	1 knock-out for cable entry, clamping capacity: 14 mm 2 knock-outs for Pg 13 cable gland and ISO M20, clamping capacity: 12 mm
Sale per indivisible quantity	1
IP degree of protection	IP66 conforming to IEC 60529 IP67 conforming to IEC 60529 IP69 conforming to IEC 60529 IP69K conforming to ISO 20653 Type 13 conforming to UL 50E Type 12 conforming to UL 50E Type 4 conforming to UL 50E Type 4X conforming to UL 50E

## Complementary

Assembly style	For customer assembly
Number of horizontal rows	1
Number of vertical rows	1
CAD overall width	68 mm
CAD overall height	68 mm
CAD overall depth	53 mm
Product weight	0.116 kg
Resistance to high pressure washer	7000000 Pa at 55 °C, distance : 0.1 m
Mounting of block	Front mounting Rear mounting
electrical composition code	SR1 SF1 MR1 MF1

Main group	1 cut-out
Group of product	Standard yellow
<b>Environment</b>	
Protective treatment	TH
Ambient air temperature for storage	-40...70 °C
Ambient air temperature for operation	-40...70 °C
Overvoltage category	Class II conforming to IEC 60536
IK degree of protection	IK05 conforming to IEC 62262
Standards	IEC 60947-5-5 IEC 60947-5-4 JIS C8201-5-1 IEC 60947-1 IEC 60947-5-1 JIS C8201-1

## Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.0 cm
Package 1 Width	7.0 cm
Package 1 Length	7.5 cm
Package 1 Weight	115.0 g
Unit Type of Package 2	S03
Number of Units in Package 2	60
Package 2 Height	30 cm
Package 2 Width	30 cm
Package 2 Length	40 cm
Package 2 Weight	7.362 kg

## Contractual warranty

Warranty	18 months
----------	-----------



## Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

### Environmental footprint

Total lifecycle Carbon footprint 1

Environmental Disclosure [Product Environmental Profile](#)

## Use Better

### Materials and Substances

Packaging made with recycled cardboard Yes

Packaging without single use plastic Yes

[EU RoHS Directive](#) Pro-active compliance (Product out of EU RoHS legal scope)

REACH Regulation [REACH Declaration](#)

## Use Again

### Repack and remanufacture


End of life manual availability [End of Life Information](#)

Take-back No

WEEE Label  The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins

## Dimensions Drawings


## Dimensions

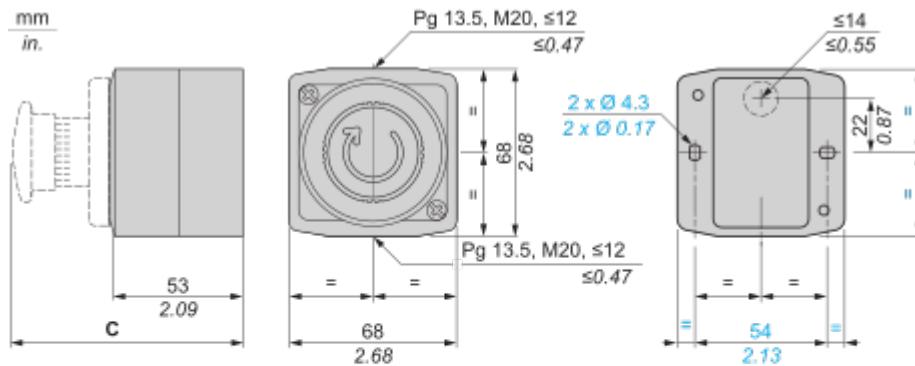

C	mm	in.
	XALK84W3BE, XALK84W3BG, XALK84W4BE, XALK84W4BG, XALK84W2ME, XALK84W2MG	96 3.78
	XALK178W3B140E, XALK178W3B140G XALK178W4B140E, XALK178W4B140G	93 3.66

## Technical Illustration

## Dimensions

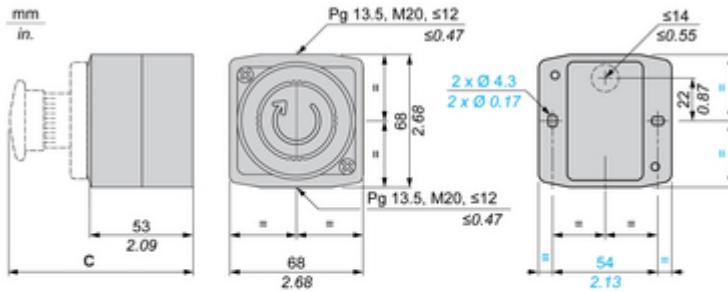

C	mm	in.
XALK84W3BE, XALK84W3BG, XALK84W4BE, XALK84W4BG, XALK84W2ME, XALK84W2MG	96	3.78
XALK178W3B140E, XALK178W3B140G, XALK178W4B140E, XALK178W4B140G	93	3.66

Image of product / Alternate images

Alternative

---



