

# Product data sheet

Specifications

SQUARE D



Mini circuit breaker, QO, 50A, 3 pole, 120/240VAC, 10kA, bolt on

QOB350

**Product availability:** Stock - Normally stocked in distribution facility

## Main

Product	Miniature circuit-breaker
Range	QO
Current Rating	50 A
Voltage Rating	120/240 V AC 240 V AC 120 V AC
Mounting Type	Bolt-on
Number of Poles	3P
Circuit Breaker Type	Standard
Ratings	HACR rated
Electrical Connection	Box lugs

## Complementary

Interrupt Rating	10 kA 120/240 V AC 10 kA 240 V AC 10 kA 120 V AC
Number of Panel Spaces	3
Wire Size	AWG 8...AWG 2 copper or aluminium
Tightening Torque	44.3 lbf.in (5 N.m)
Height	3.1 in (79 mm)
Width	2.2 in (57 mm)
Depth	2.9 in (74 mm)
Product Weight	0.851 lb(US) (0.386 kg)

## Environment

Certifications	UL Listed CSA
Ambient Rating	104 °F (40 °C)

## Ordering and shipping details

Category	US10DE200015
Discount Schedule	ODE2
GTIN	785901417163
Returnability	Yes

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

---

Country of origin	MX
-------------------	----

## Packing Units

---

Unit Type of Package 1	PCE
------------------------	-----

Nbr. of units in pkg.	1
-----------------------	---

Package 1 Height	2.20 in (5.59 cm)
------------------	-------------------

Package 1 Width	3.00 in (7.62 cm)
-----------------	-------------------

Package 1 Length	3.60 in (9.14 cm)
------------------	-------------------

Package weight(Lbs)	13.60 oz (385.56 g)
---------------------	---------------------

Unit Type of Package 2	BB1
------------------------	-----

Number of Units in Package 2	3
------------------------------	---

Package 2 Height	3.40 in (8.636 cm)
------------------	--------------------

Package 2 Width	2.80 in (7.112 cm)
-----------------	--------------------

Package 2 Length	6.90 in (17.526 cm)
------------------	---------------------

Package 2 Weight	2.58 lb(US) (1.17 kg)
------------------	-----------------------

Unit Type of Package 3	CAR
------------------------	-----

Number of Units in Package 3	36
------------------------------	----

Package 3 Height	3.40 in (8.636 cm)
------------------	--------------------

Package 3 Width	14.20 in (36.068 cm)
-----------------	----------------------

Package 3 Length	21.60 in (54.864 cm)
------------------	----------------------

Package 3 Weight	31.90 lb(US) (14.47 kg)
------------------	-------------------------

## Contractual warranty

---

Warranty	18 months
----------	-----------



## Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

### Environmental footprint

Carbon footprint (kg CO2 eq, Total Life cycle) **20**

Environmental Disclosure [Product Environmental Profile](#)

## Use Better

### Materials and Substances

Packaging made with recycled cardboard **No**

Packaging without single use plastic **Yes**

[EU RoHS Directive](#) **Compliant**

SCIP Number **Af42fb01-813d-40c0-ae28-b8b3299dbc99**

REACH Regulation [REACH Declaration](#)

Halogen content performance **Halogen free product**

## Use Again

### Repack and remanufacture


Circularity Profile **No need of specific recycling operations**

Take-back **No**

WEEE Label  The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

## Technical Illustration

## Dimensions

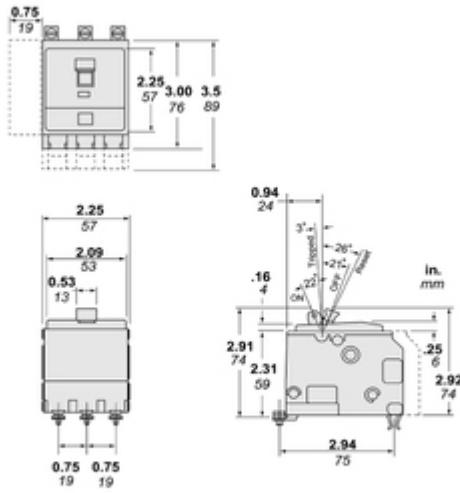

Dimensions are approximate. Refer to technical documentation for additional detail.