


Product data sheet

Specifications

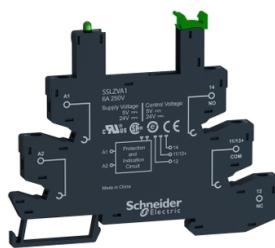

socket equipped with LED and protection circuit, Harmony Solid State Relays, for SSL relays, spring terminals, 5 to 24V DC

SSLZRA1

Product availability: Stock - Normally stocked in distribution facility

Main

Range of Product	Harmony Solid State Relays
Device short name	SSLZ
Product or Component Type	Socket for SSL1
Product compatibility	Solid state relay SSL NO 24 V DC Solid state relay SSL NO 5 V DC
[Ith] conventional free air thermal current	6 A
Switching voltage	5 V DC 24 V DC
[Ue] rated operational voltage	< 250 V DC

Complementary

Shape of pin	Flat
Contact terminal arrangement	Separate
Connections - terminals	Spring terminals, 1 x 0.2...1 x 1.5 mm ² AWG 24...AWG 16) solid without cable end Spring terminals, 1 x 0.2...1 x 1.5 mm ² AWG 24...AWG 16) flexible with cable end
Clamping force	10...40 N
Fixing mode	Clip-on (35 mm DIN rail)
[U_{imp}] rated impulse withstand voltage	3.6 kV
Overvoltage category	III
Pollution degree	3
Sale per indivisible quantity	10
Local signalling	LED (green) for input status
Width	0.2 in (6.2 mm)
Height	4.0 in (101 mm)
Depth	3.09 in (78.6 mm)
Product Weight	0.0628 lb(US) (0.0285 kg)

Environment

Standards	IEC 61984
Product Certifications	UL 508 CSA C22-2 No 14
Marking	CE

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Ambient Air Temperature for Storage	-40...185 °F (-40...85 °C)
Ambient Air Temperature for Operation	-40...158 °F (-40...70 °C)
IP Degree of Protection	IP20
Flame retardance	V0 conforming to UL 94

Ordering and shipping details

Category	US10CP221127
Discount Schedule	0CP2
GTIN	3606480580161
Returnability	Yes
Country of origin	CN

Packing Units

Unit Type of Package 1	PCE
Nbr. of units in pkg.	1
Package 1 Height	0.24 in (0.600 cm)
Package 1 Width	3.15 in (8.000 cm)
Package 1 Length	4.13 in (10.500 cm)
Package weight(Lbs)	0.811 oz (23.000 g)
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Height	3.35 in (8.500 cm)
Package 2 Width	2.80 in (7.100 cm)
Package 2 Length	4.21 in (10.700 cm)
Package 2 Weight	8.889 oz (252.000 g)
Unit Type of Package 3	S03
Number of Units in Package 3	300
Package 3 Height	11.81 in (30.000 cm)
Package 3 Width	11.81 in (30.000 cm)
Package 3 Length	15.75 in (40.000 cm)
Package 3 Weight	18.254 lb(US) (8.280 kg)



Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint

Carbon footprint (kg CO2 eq, Total Life cycle)

1

Use Better

Materials and Substances

Packaging made with recycled cardboard

Yes

Packaging without single use plastic

Yes

[EU RoHS Directive](#)

Pro-active compliance (Product out of EU RoHS legal scope)

REACH Regulation

[REACH Declaration](#)

California proposition 65

WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](#)

Use Again


Repack and remanufacture

Take-back

No

Dimensions Drawings


Dimensions

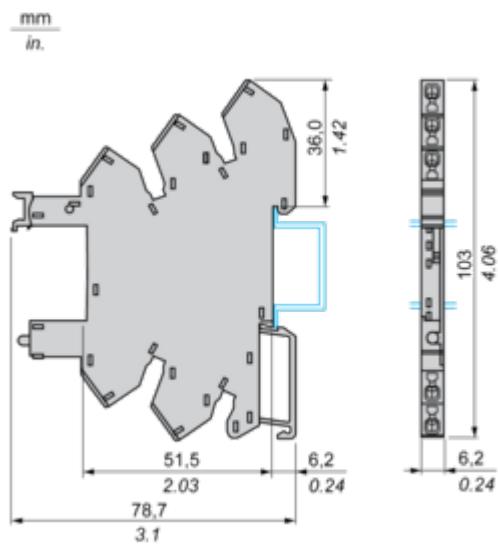

Connections and Schema

Wiring Diagram


Wiring Diagram for DC Output

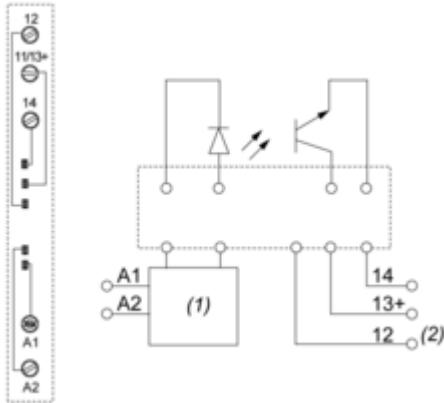

(1) Protection circuit

(2) Terminal 12 is not in use for SSL Relay

Example of RSLZ2 Bus Jumper Mounting on Sockets

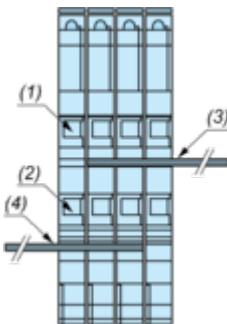

(1) A1

(2) A2

(3) Bus jumper polarity A1

(4) Bus jumper polarity A2

Technical Illustration

Dimensions

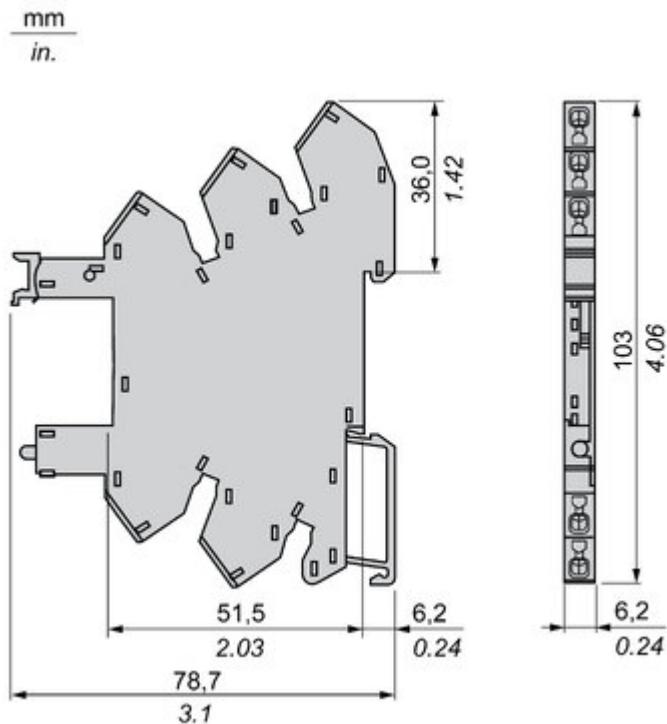


Image of product in real life situation

