

Product data sheet

Specifications



Complete pre wired monolithic tower light, Harmony XVC, plastic, red orange, 60mm, base mounting, steady or flashing, with buzzer 70...85 dB, 24V AC DC

XVC6B25SK

Product availability: Non-Stock - Not normally stocked in distribution facility

Main

Range of Product	Harmony XVC6
Product or Component Type	Complete pre-wired monolithic tower light
Beacon or indicator bank unit type	2 illuminated units
Sound signalling	Buzzer
Mounting diameter	2.4 in (60 mm)
Component name	XVC
Light source	LED steady or flashing red LED steady or flashing orange
[Us] rated supply voltage	24 V
Supply circuit type	AC/DC
Noise level	70...85 dB continuous or intermittent tone)1 m

Complementary

Material	Polycarbonate: illuminated unit ABS (acrylonitrile butadiene-styrene): base unit PBT + ABS (UL94HB): top cover
Product mounting	On base
Cable cross section	0.0005 in ² (0.33 mm ²)
AWG Gauge	AWG 22
Cable length	33.5 in (850 mm)
Marking	CE
[Uimp] rated impulse withstand voltage	0.8 kV
Current Consumption	90 mA
Fundamental frequency	2.23 kHz
Flashing frequency	1 Hz
Product Weight	0.55 lb(US) (0.25 kg)
Height	6.3 in (160.8 mm)

Environment

Standards	IEC 61000-6-4 IEC 61000-6-3 IEC 61000-6-2
-----------	---

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Product Certifications	UL
Protective treatment	TC
Ambient Air Temperature for Storage	-31...158 °F (-35...70 °C)
Ambient Air Temperature for Operation	14...122 °F (-10...50 °C)
Electrical shock protection class	Class II conforming to IEC 61140
IP degree of protection	IP54 flat surface installation IEC 60529

Ordering and shipping details

Category	US100XV22617
Discount Schedule	00XV
GTIN	3606480032707
Returnability	Yes
Country of origin	ID

Packing Units

Unit Type of Package 1	PCE
Nbr. of units in pkg.	1
Package 1 Height	3.39 in (8.6 cm)
Package 1 Width	3.46 in (8.8 cm)
Package 1 Length	19.76 in (50.2 cm)
Package weight(Lbs)	16.9 oz (480.0 g)
Unit Type of Package 2	S04
Number of Units in Package 2	12
Package 2 Height	11.81 in (30.0 cm)
Package 2 Width	15.75 in (40.0 cm)
Package 2 Length	23.62 in (60.0 cm)
Package 2 Weight	15.673 lb(US) (7.109 kg)

Contractual warranty

Warranty	18 months
----------	-----------



Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Use Better

Materials and Substances

Packaging made with recycled cardboard	Yes
Packaging without single use plastic	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Use Again

Repack and remanufacture


Take-back	No
-----------	----

Dimensions Drawings

Pre-assembled and Pre-wired Tower Light

Dimensions

Below drawing shows the maximum configuration of the product. Select the number of stages according to the product characteristics in order to get **b** dimension.

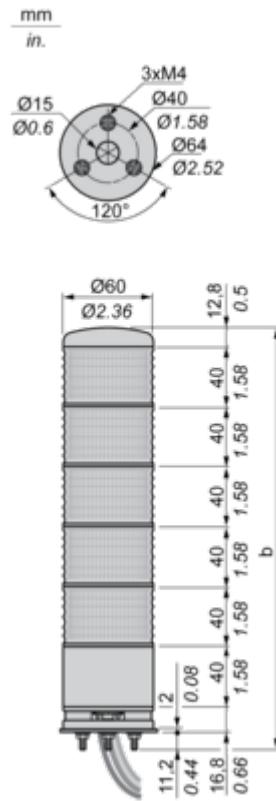


No. of illuminated units	b (mm)	b (in.)
1 stage	120.8	4.76
2 stages	160.8	6.33
3 stages	200.8	7.90
4 stages	240.8	9.48
5 stages	280.8	11.06

Mounting and Clearance

Pre-assembled and Pre-wired Tower Light**Mounting on Horizontal Support (Direct or with Fixing Plate)**

Panel cut-out

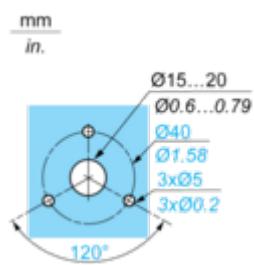

Technical Illustration

Dimensions

