

Product data sheet

Specifications



Head for spring return push button,
Harmony 9001K, metal, flush, 7
colours choice, 30mm

9001KR1U

Main

Range of product	Harmony 9001K
Product or component type	Head for push-button
Device short name	9001K
Operator profile	flush, unmarked
Operator additional information	Metal guard

Complementary

Mounting diameter	30 mm
Shape of signaling unit head	Round
Type of operator	spring return
Product weight	0.087 kg
Bezel material	Metal
Cap/operator or lens colour	7 colours choice
Operator profile	Flush
Type of operator	Spring return
Contacts type and composition	Without contact block

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	9.500 cm
Package 1 Width	5.500 cm
Package 1 Length	5.000 cm
Package 1 Weight	104.000 g
Unit Type of Package 2	S01
Number of Units in Package 2	24
Package 2 Height	15.000 cm
Package 2 Width	15.000 cm
Package 2 Length	40.000 cm
Package 2 Weight	2.622 kg

Contractual warranty

Warranty

18 months



Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Use Better

Materials and Substances

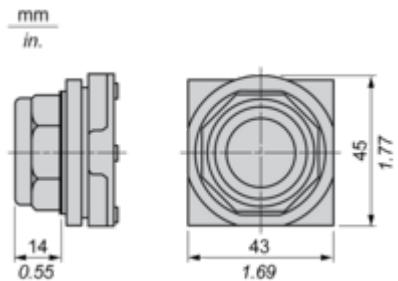
Packaging made with recycled cardboard	Yes
Packaging without single use plastic	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
SCIP Number	Ae0c4eb9-0bfb-40a4-851f-5c619fbe777d
REACH Regulation	REACH Declaration
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Use Again

Repack and remanufacture

Take-back	No
-----------	----

Dimensions Drawings

Dimensions

Mounting and Clearance

Contact Block Mounting Position

Top and Rear views



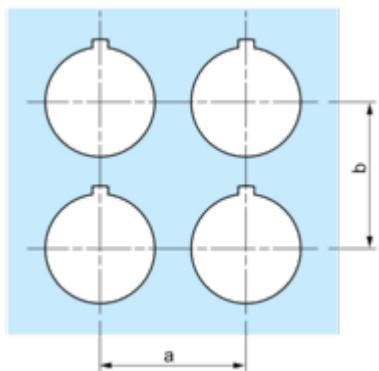
(1) It is possible to mount up to 3 levels of contacts blocks (maximum of 6 contacts blocks)

(2) Operator

(3) Locating notch

(4) Side 1

(5) Side 2

Panel Cut-Out**Clearance**

Legend plate	a min.		b min.	
	mm	in.	mm	in.
9001KN2..	57.2	2.25	44.5	1.75
9001KN3..	57.2	2.25	50.8	2.00

Individual Cut-outs Details

2 alternatives

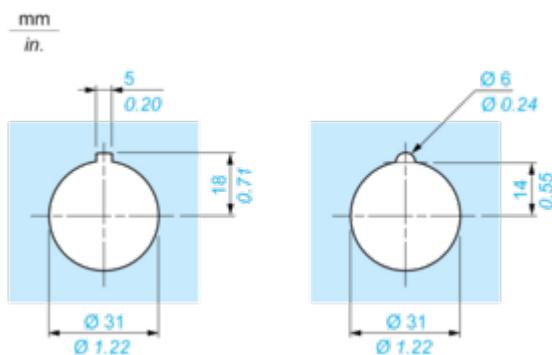


Image of product / Alternate images

Alternative





