

# Product data sheet

## Characteristics

# TCSESSU083FN0

## ConneXium Standard Unmanaged Switch - 8 ports for copper



### Main

Range of product	ConneXium
Product or Component Type	Ethernet TCP/IP unmanaged switch
Concept	Transparent Ready
Communication port protocol	Ethernet TCP/IP
Port Ethernet	10/100BASE-TX - 8 copper cable
Maximum number of switches in cascade	Unlimited

### Complementary

Integrated connection type	Shielded RJ45 copper cable
Transmission support medium	Twisted shielded pairs cable CAT 5E copper cable
Maximum cable distance between devices	328.08 ft (100 m) copper cable
[Us] rated supply voltage	12...24 V
Supply voltage limits	9.6...32 V DC SELV
Power consumption in W	1.5 W
Electrical connection	Removable connector 3 ways power supply
Mounting Support	35 mm symmetrical DIN rail
Marking	CE UL RCM
Local signalling	For power supply 1 LED (green) For data rate (ETH LINK) 1 LED per channel (yellow) For link status 1 dual colour LED (green/yellow)
Ethernet cabling system	TF switches
Width	1.50 in (38 mm)
Height	4.02 in (102 mm)
Depth	3.11 in (79 mm)
Product Weight	0.33 lb(US) (0.150 kg)

### Environment

Ambient Air Temperature for Operation	32...140 °F (0...60 °C)
Relative Humidity	10...95 % non-condensing
IP degree of protection	IP30
Directives	2014/35/EU - low voltage directive 2014/30/EU - electromagnetic compatibility
Standards	UL 61010 EN/IEC 61131
Product certifications	CE UL RCM

### Ordering and shipping details

GTIN	3606481337429
Nbr. of units in pkg.	1
Package weight(Lbs)	10.93 oz (310 g)

## Packing Units

Unit Type of Package 1	PCE
Package 1 Height	2.44 in (6.2 cm)
Package 1 width	6.34 in (16.1 cm)
Package 1 Length	9.45 in (24 cm)
Unit Type of Package 2	S04
Number of Units in Package 2	20
Package 2 Weight	15.21 lb(US) (6.9 kg)
Package 2 Height	11.81 in (30 cm)
Package 2 width	15.75 in (40 cm)
Package 2 Length	23.62 in (60 cm)


## Contractual warranty

Warranty	18 months
----------	-----------

---

Dimensions

---

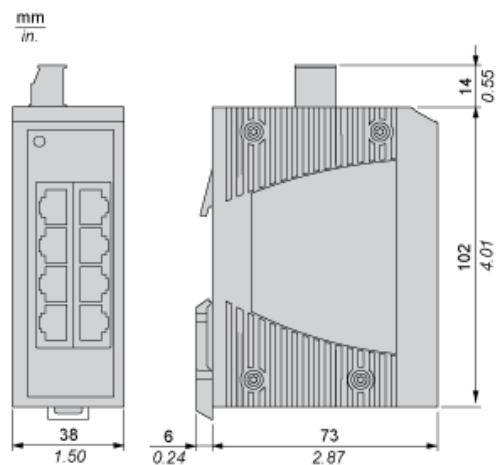

---

### Power Wiring

---

