

Product data sheet

Specifications



Harmony, Socket, for 725 power relays, 30 A, 6 pins, screw connectors, separate contact

70-725-1

Main

Product Range	Harmony Electromechanical Relays
Product Type	Socket
Number of Terminals	6
Switch Function	DPST
Contact Composition	2 NO

Complementary

Rated Current	30 A
[Ue] rated operational voltage	300 V
Connections Terminals	screw terminal, clamping connection capacity: 6 mm ² , AWG 10 solid screw terminal, clamping connection capacity: 2 x 0.5...2 x 6 mm ² , AWG 20...AWG 10 stranded
Tightening Torque	Screw: 1.2 N.m
Fixing Mode	Clip-on, for 35 mm symmetrical DIN rail
Product Weight	67 g
Depth	70.5 mm

Environment

Flame Retardance	UL94-V0
------------------	---------

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.08 cm
Package 1 Width	5.4 cm
Package 1 Length	2.35 cm
Package 1 Weight	67 g



Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Use Better

Materials and Substances

Packaging made with recycled cardboard	Yes
--	-----

Packaging without single use plastic	Yes
--------------------------------------	-----


Use Again

Repack and remanufacture


Take-back	No
-----------	----

Dimensions Drawings


Dimensions

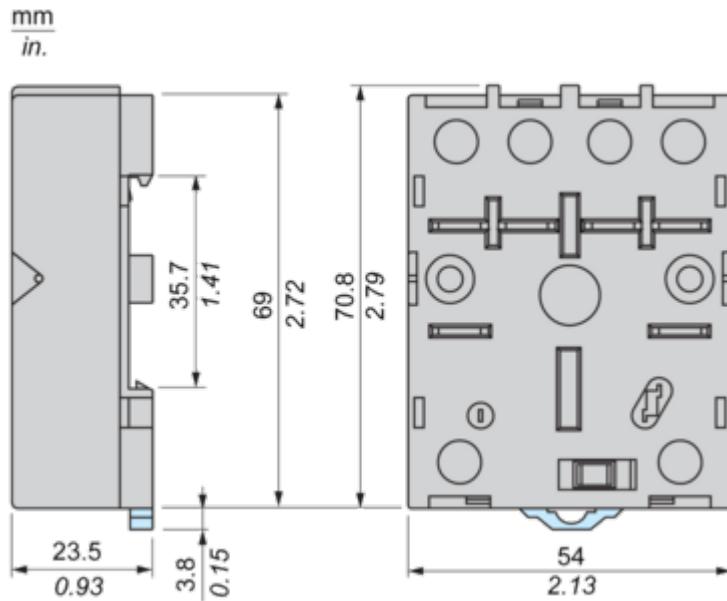

Connections and Schema

 Wiring Diagram

IEC:	▲
NEMA:	▼

 

Technical Illustration

Dimensions

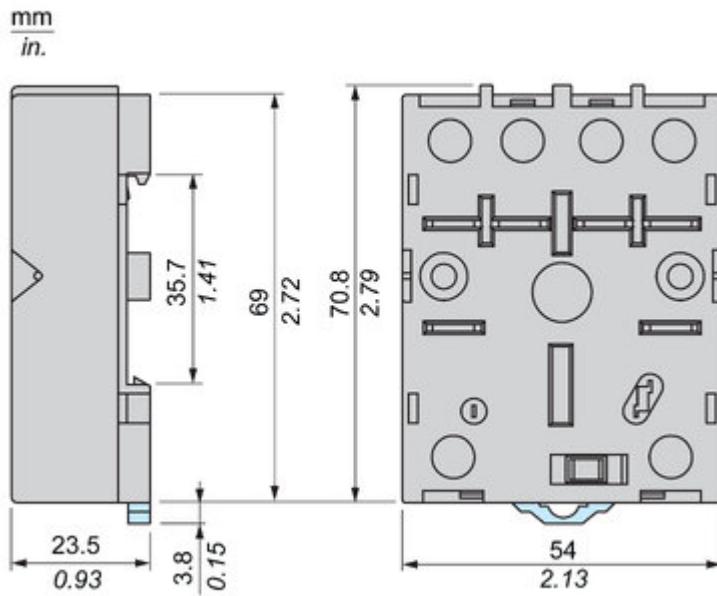


Image of product in real life situation

