

# Product data sheet

Specifications



Empty control station without  
hinges, Harmony XAP, XB2 SL,  
plastic, grey, undrilled,  
85x146x87mm

XAPA1100

## Main

|                               |  |
|-------------------------------|--|
| Range of product              | Harmony XAP  |
| Product or component type     | Empty control station without hinges   |
| Device short name             | XAPA   |
| Product front plate size      | 85 x 146 mm  |
| Usable depth                  | 83 mm  |
| Number of cut-out             | Undrilled  |
| Colour of base of enclosure   | Grey   |
| Colour of cover               | Grey   |
| Material                      | Glass reinforced polyester   |
| Cable entry                   | Undrilled  |
| Device mounting               | Flush  |
| IP degree of protection       | IP65 conforming to IEC 60529<br>IP69 conforming to NF C 20-010<br>IP69K  |
| Resistance to chemical agents | High resistant to acids<br>High resistant to all solvents<br>High resistant to bases<br>High resistant to diesel<br>High resistant to mineral salts<br>High resistant to oils and greases<br>High resistant to petrol<br>High resistant to sea water |

## Complementary

|                  |   |
|------------------|---|
| Product weight   | 0.47 kg   |
| Flame retardance | M3 conforming to CSTB<br>VO conforming to UL 94 |

## Environment

|                                       |  |
|---------------------------------------|--|
| Protective treatment                  | TC<br>TH   |
| Ambient air temperature for storage   | -40...70 °C  |
| Ambient air temperature for operation | -40...70 °C  |
| Overvoltage category                  | Class II conforming to IEC 60536<br>Class II conforming to NF C 20-030 |
| Fire resistance                       | 850 °C conforming to NF C 20-455<br>960 °C conforming to IEC 92        |

## Packing Units

---

|                              |           |
|------------------------------|-----------|
| Unit Type of Package 1       | PCE       |
| Number of Units in Package 1 | 1         |
| Package 1 Height             | 11.064 cm |
| Package 1 Width              | 9.000 cm  |
| Package 1 Length             | 15.500 cm |
| Package 1 Weight             | 508.000 g |
| Unit Type of Package 2       | S06       |
| Number of Units in Package 2 | 113       |
| Package 2 Height             | 75.000 cm |
| Package 2 Width              | 60.000 cm |
| Package 2 Length             | 80.000 cm |
| Package 2 Weight             | 71.873 kg |

## Contractual warranty

---

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|



## Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

### Environmental footprint

Total lifecycle Carbon footprint 3

Environmental Disclosure [Product Environmental Profile](#)

## Use Better

### Materials and Substances

Packaging made with recycled cardboard Yes

Packaging without single use plastic Yes

[EU RoHS Directive](#) Pro-active compliance (Product out of EU RoHS legal scope)

REACH Regulation [REACH Declaration](#)

California proposition 65 WARNING: This product can expose you to chemicals including: Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](#)

## Use Again


### Repack and remanufacture

End of life manual availability No need of specific recycling operations

Take-back No

## Dimensions Drawings

## Dimensions and Fixing

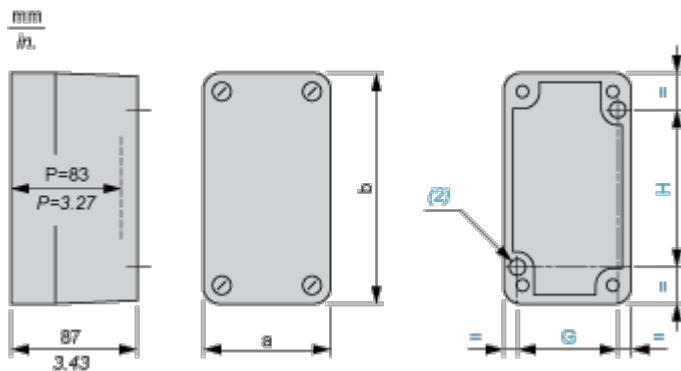

(2) 2 x Ø 5.6 mm/0.22 in. holes, depth 12 mm/0.47 in.

P Usable depth

| a  |      | b   |      | G  |      | H   |      |
|----|------|-----|------|----|------|-----|------|
| mm | in.  | mm  | in.  | mm | in.  | mm  | in.  |
| 85 | 3.35 | 146 | 5.75 | 70 | 2.76 | 105 | 4.13 |

Image of product / Alternate images

Alternative

---

