

Product data sheet

Specifications

SQUARE D



Mini circuit breaker, QO, 60A, 3 pole, 120/240VAC, 10kA, bolt on

QOB360

Product availability: Stock - Normally stocked in distribution facility

Main

Product	Miniature circuit-breaker
Range	QO
Current Rating	60 A
Voltage Rating	120/240 V AC 240 V AC 120 V AC
Mounting Type	Bolt-on
Number of Poles	3P
Circuit Breaker Type	Standard
Ratings	HACR rated
Electrical Connection	Box lugs

Complementary

Interrupt Rating	10 kA 120/240 V AC 10 kA 240 V AC 10 kA 120 V AC
Number of Panel Spaces	3
Wire Size	AWG 8...AWG 2 copper or aluminium
Tightening Torque	44.3 lbf.in (5 N.m)
Height	3.1 in (79 mm)
Width	2.2 in (57 mm)
Depth	2.9 in (74 mm)
Product Weight	0.851 lb(US) (0.386 kg)

Environment

Certifications	UL Listed CSA
Ambient Rating	104 °F (40 °C)

Ordering and shipping details

Category	US10DE200015
Discount Schedule	ODE2
GTIN	785901417187
Returnability	Yes

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Country of origin	MX
-------------------	----

Packing Units

Unit Type of Package 1	PCE
------------------------	-----

Nbr. of units in pkg.	1
-----------------------	---

Package 1 Height	3.30 in (8.382 cm)
------------------	--------------------

Package 1 Width	3.00 in (7.620 cm)
-----------------	--------------------

Package 1 Length	3.50 in (8.890 cm)
------------------	--------------------

Package weight(Lbs)	13.600 oz (385.553 g)
---------------------	-----------------------

Unit Type of Package 2	BB1
------------------------	-----

Number of Units in Package 2	3
------------------------------	---

Package 2 Height	3.40 in (8.636 cm)
------------------	--------------------

Package 2 Width	3.50 in (8.890 cm)
-----------------	--------------------

Package 2 Length	6.80 in (17.272 cm)
------------------	---------------------

Package 2 Weight	2.599 lb(US) (1.179 kg)
------------------	-------------------------

Unit Type of Package 3	CAR
------------------------	-----

Number of Units in Package 3	36
------------------------------	----

Package 3 Height	3.70 in (9.398 cm)
------------------	--------------------

Package 3 Width	14.25 in (36.195 cm)
-----------------	----------------------

Package 3 Length	21.70 in (55.118 cm)
------------------	----------------------

Package 3 Weight	32.099 lb(US) (14.560 kg)
------------------	---------------------------

Contractual warranty

Warranty	18 months
----------	-----------



Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint

Carbon footprint (kg CO2 eq, Total Life cycle) **20**

Environmental Disclosure [Product Environmental Profile](#)

Use Better

Materials and Substances

Packaging made with recycled cardboard **No**

Packaging without single use plastic **Yes**

[EU RoHS Directive](#) **Compliant**

SCIP Number **Af42fb01-813d-40c0-ae28-b8b3299dbc99**

REACH Regulation [REACH Declaration](#)

Halogen content performance **Halogen free product**

Use Again


Repack and remanufacture

Circularity Profile **No need of specific recycling operations**

Take-back **No**

Technical Illustration

Dimensions

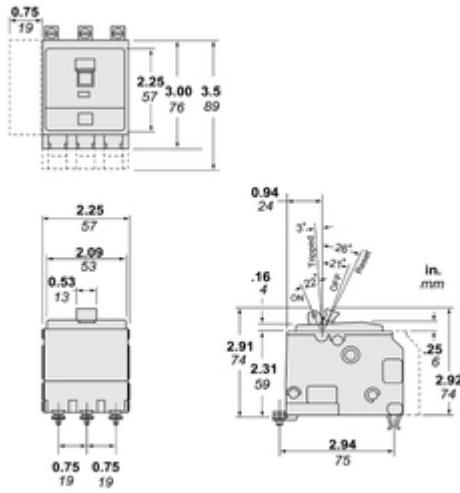

Dimensions are approximate. Refer to technical documentation for additional detail.