

Product data sheet

Specifications



Electronic alarm, Harmony XVS, black, NPN, mounting support DIN 72, 0...90dB, 16tones, 4 channels, 12...24V AC DC

XVS72BMBN

Product availability: Non-Stock - Not normally stocked in distribution facility

Main

Range of Product	Harmony XVS
Product or Component Type	Electronic alarm
Device short name	XVS

Complementary

Color	Black
Material	ABS (acrylonitrile butadiene-styrene): body PC (polycarbonate): terminal cover
Marking	CE
Overvoltage category	Class II conforming to IEC 61140
Mounting Support	72 mm DIN rail
[Us] rated supply voltage	12...24 V DC
[Uiimp] rated impulse withstand voltage	0.8 kV
Current consumption	117 mA 12 V 125 mA 24 V 158 mA 12 V 200 mA 24 V
Clamping Connection Capacity	<= 1 x 1.5 mm ²
Width	2.8 in (72 mm)
Height	2.8 in (72 mm)
Depth	2.7 in (69.3 mm)
Product Weight	0.40 lb(US) (0.18 kg)

Environment

Discrete output type	NPN
Signalling type	16 tones alarm
Standards	UL 464 IEC 61000-6-3 IEC 61000-6-2
Product Certifications	UR
Protective treatment	TC
Ambient Air Temperature for Storage	-31...158 °F (-35...70 °C)
Ambient Air Temperature for Operation	14...122 °F (-10...50 °C)

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

IP degree of protection	Panel mounted IP54 IEC 60529
Noise level	0...90 dB continuous or intermittent tone)1 m

Ordering and shipping details

Category	US100XV22617
Discount Schedule	00XV
GTIN	3606480032929
Returnability	Yes
Country of origin	ID

Packing Units

Unit Type of Package 1	PCE
Nbr. of units in pkg.	1
Package 1 Height	3.70 in (9.4 cm)
Package 1 Width	3.70 in (9.4 cm)
Package 1 Length	4.10 in (10.41 cm)
Package weight(Lbs)	0.60 lb(US) (0.27 kg)
Unit Type of Package 2	S03
Number of Units in Package 2	16
Package 2 Height	11.81 in (30 cm)
Package 2 Width	11.81 in (30 cm)
Package 2 Length	15.75 in (40 cm)
Package 2 Weight	11.283 lb(US) (5.118 kg)
Unit Type of Package 3	PAL
Number of Units in Package 3	128
Package 3 Height	23.62 in (60 cm)
Package 3 Width	31.50 in (80 cm)
Package 3 Length	50.39 in (128 cm)
Package 3 Weight	76.19 lb(US) (34.56 kg)

Contractual warranty

Warranty	18 months
----------	-----------



Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint

Carbon footprint (kg CO2 eq, Total Life cycle)

7

Use Better

Materials and Substances

Packaging made with recycled cardboard	Yes
Packaging without single use plastic	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
SCIP Number	Fe0ee3ab-dd49-4abe-bd8e-c49754e2c442
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Use Again


Repack and remanufacture

Take-back	No
-----------	----

Dimensions Drawings

Electronic Alarm

Dimensions

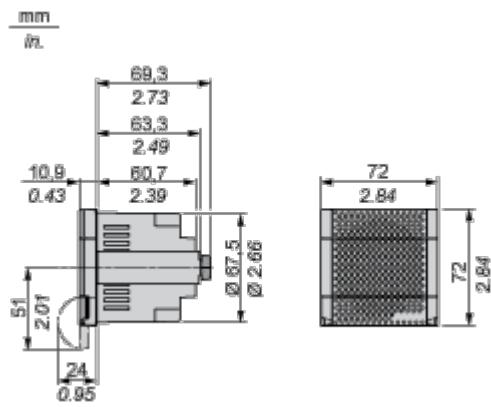

Technical Illustration

Dimensions

