

# Product data sheet

Specifications



30mm Push Button, Type K,  
selector switch, 3 position, C cam,  
spring return both sides to center,  
black knob

9001KS53B

**Product availability:** Stock - Normally stocked in distribution facility

## Main

Range of Product	Harmony 9001K
Product or Component Type	Head for selector switch
Device short name	K
Type of operator	spring return
Operator profile	Black standard knob

## Complementary

Bezel material	Metal
Mounting diameter	1.2 in (30 mm)
Operator position information	3 positions
Contacts type and composition	Without contact block
Device presentation	Basic element
Cap/operator or lens colour	Black
Operator profile	Standard handle
Type of operator	Spring return
Size	30 mm
Return	Both sides to centre
Cam profile	3

## Environment

NEMA degree of protection	NEMA 1/2/3/3R/4/6/12/13
Product Certifications	UL listed file E42259 CCN NKCR CE CSA LR24590 class 3211 03

## Ordering and shipping details

Category	US10CS121426
Discount Schedule	OCS1
GTIN	785901322740
Returnability	Yes
Country of origin	MX

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

## Packing Units

---

Unit Type of Package 1	PCE
Nbr. of units in pkg.	1
Package 1 Height	2.80 in (7.112 cm)
Package 1 Width	2.30 in (5.842 cm)
Package 1 Length	2.10 in (5.334 cm)
Package weight(Lbs)	4.32 oz (122.47 g)

## Contractual warranty

---

Warranty	18 months
----------	-----------



Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

## Use Better

### Materials and Substances

Packaging made with recycled cardboard	Yes
Packaging without single use plastic	Yes
<a href="#">EU RoHS Directive</a>	Pro-active compliance (Product out of EU RoHS legal scope)
SCIP Number	Ae0c4eb9-0bfb-40a4-851f-5c619fbe777d
REACH Regulation	<a href="#">REACH Declaration</a>
California proposition 65	<b>WARNING:</b> This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to <a href="#">www.P65Warnings.ca.gov</a>


## Use Again

### Repack and remanufacture

Take-back	No
WEEE Label	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

## Technical Illustration

## Dimensions

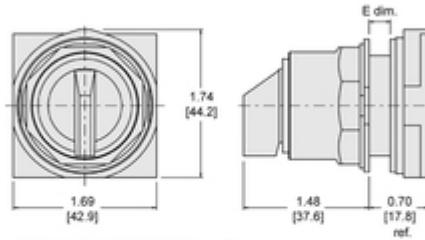

Panel Thickness E dim. in. [mm]	Number of Gasket in. [mm]
1/16 [1.6]	4
1/8 (3.2)	3
3/16 (4.8)	2
1/4 (6.4)	1

## Offer Marketing Illustration

## Product benefits / Features

## Technical Benefits

## Harmony 9001K



## Offer Marketing Illustration

### Product benefits / Features

### Features

#### Harmony 9001K



-   
Improved security thanks to finger-safe contact blocks and light modules
-   
Robustness to withstand the harshest environments
-   
Single screw Contact Block Fastening
-   
Large metal set of accessories to customize your product
-   
Automatic self-grounding operators without additional wiring

Image of product / Alternate images

Alternative

---



