


# Product data sheet

Specifications

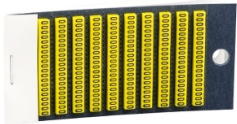

Marker, Linergy TR cable ends,  
blue, clipin type, character 6,  
Numeric, set of 200

AR1MC016

## Main

|                                       |                     |
|---------------------------------------|---------------------|
| Range of product                      | Cable ends          |
| Accessory / separate part designation | Marker              |
| Accessory / separate part type        | Marker              |
| Accessory / separate part category    | Marking accessories |
| Accessory / separate part destination | Markable cable end  |
| Background colour                     | Blue                |
| Marking                               | 6                   |
| Standards                             | NF C 93-011         |
| Sale per indivisible quantity         | 200                 |

## Complementary

|                   |         |
|-------------------|---------|
| Type of marking   | Numeric |
| Colour of marking | Black   |
| Product weight    | 0.01 kg |

## Packing Units

|                              |           |
|------------------------------|-----------|
| Unit Type of Package 1       | PCE       |
| Number of Units in Package 1 | 1         |
| Package 1 Height             | 0.300 cm  |
| Package 1 Width              | 0.300 cm  |
| Package 1 Length             | 0.500 cm  |
| Package 1 Weight             | 0.100 g   |
| Unit Type of Package 2       | BB1       |
| Number of Units in Package 2 | 200       |
| Package 2 Height             | 0.400 cm  |
| Package 2 Width              | 4.800 cm  |
| Package 2 Length             | 10.300 cm |
| Package 2 Weight             | 8.000 g   |
| Unit Type of Package 3       | S01       |
| Number of Units in Package 3 | 48000     |
| Package 3 Height             | 15.000 cm |

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

|                  |           |
|------------------|-----------|
| Package 3 Width  | 15.000 cm |
| Package 3 Length | 40.000 cm |
| Package 3 Weight | 2.405 kg  |

## Contractual warranty

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Use Better

|  Materials and Substances |                                                            |
|------------------------------------------------------------------------------------------------------------|------------------------------------------------------------|
| Packaging made with recycled cardboard                                                                     | Yes                                                        |
| Packaging without single use plastic                                                                       | No                                                         |
| <a href="#">EU RoHS Directive</a>                                                                          | Pro-active compliance (Product out of EU RoHS legal scope) |
| Halogen-free status                                                                                        | Halogen free plastic parts product                         |

Use Again

|  Repack and remanufacture |                                          |
|------------------------------------------------------------------------------------------------------------|------------------------------------------|
| End of life manual availability                                                                            | No need of specific recycling operations |
| Take-back                                                                                                  | No                                       |