

Product data sheet

Specifications



Socket, General Purpose Relays, for 788 relays, 3PDT, 11 pins, screws clamp terminals, 15A, 300V

70-463-1

Product availability: Stock - Normally stocked in distribution facility

Main

Product Range	Legacy
Product Type	Socket
Product Compatibility	relay 788XBXR/XCXR
Number of Terminals	11
Switch Function	3PDT
Contact Composition	3 NO + 3 NC

Complementary

Rated Current	15 A
[Ue] rated operational voltage	300 V
Contact Terminal Arrangement	Mixed
Connections Terminals	screw clamp terminals solid for output screw clamp terminals stranded for output
Tightening Torque	Screw < 1 N.m Screw < 0.8 N.m
Fixing Mode	By screw M3.5, M3.5 panel Clip-on 35 mm DIN rail
Shape of Screw Head	Combination roundhead
Product Weight	1.8 oz (51 g)
Width	141.08 ft (43.00 m)
Depth	2.2 in (57 mm)

Environment

Ambient Air Temperature for Storage	-40...221 °F (-40...105 °C)
Ambient Air Temperature for Operation	-40...131 °F (-40...55 °C)
Flame Retardance	UL94-V0
Product Certifications	UL CSA CE

Ordering and shipping details

Category	US10CP221127
Discount Schedule	OCP2
GTIN	3606480277955

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Returnability	Yes
---------------	-----

Country of origin	CN
-------------------	----

Packing Units

Unit Type of Package 1	PCE
------------------------	-----

Nbr. of units in pkg.	1
-----------------------	---

Package 1 Height	3.15 in (8 cm)
------------------	----------------

Package 1 Width	1.69 in (4.3 cm)
-----------------	------------------

Package 1 Length	1.02 in (2.6 cm)
------------------	------------------

Package weight(Lbs)	1.8 oz (51 g)
---------------------	---------------



Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint

Carbon footprint (kg CO2 eq, Total Life cycle)

1

Use Better

Materials and Substances

Packaging made with recycled cardboard

Yes

Packaging without single use plastic

Yes

[EU RoHS Directive](#)

Pro-active compliance (Product out of EU RoHS legal scope)

REACH Regulation

[REACH Declaration](#)

California proposition 65

WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](#)

Use Again

Repack and remanufacture

Circularity Profile

No need of specific recycling operations

Take-back

No

Dimensions Drawings

Approximate Dimensions

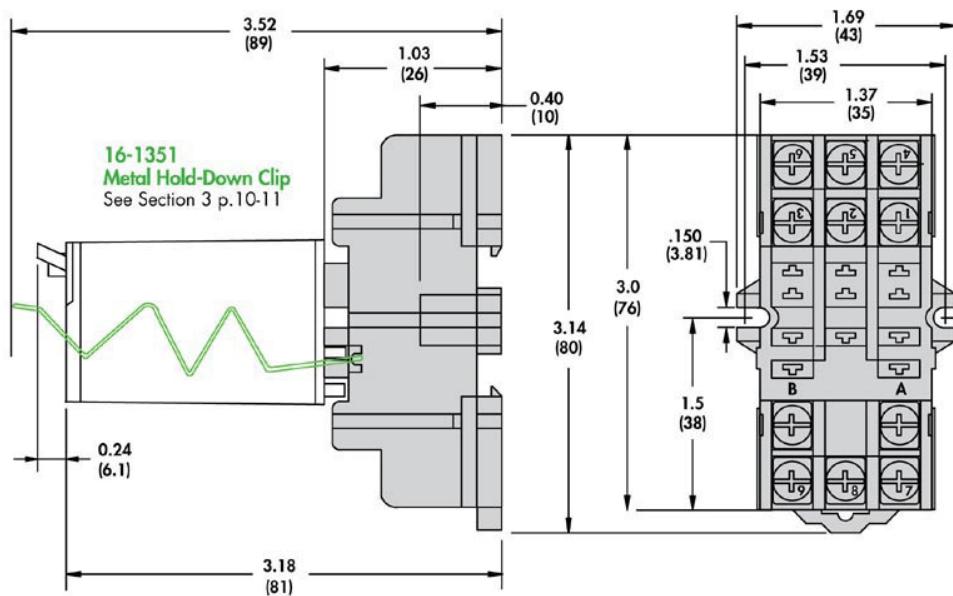


Image of product / Alternate images

Alternative



