

Product data sheet

Specifications



EMC radio interference input filter - for variable speed drive

VW3A4417

Main

Range of product	Altivar
Product or component type	EMC input filter
Range compatibility	Altivar 12
Product compatibility	ATV12H075F1 ATV12HU15M2 ATV12HU22M2
Product specific application	Radio interference input filter

Complementary

Product weight	1.455 kg
----------------	----------

Environment

Standards	Environment 1 category C2 IEC 61800-3 Environment 1 category C3 IEC 61800-3 Environment 2 category C3 IEC 61800-3
-----------	-------------------------------------------------------------------------------------------------------------------------

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	9.000 cm
Package 1 Width	38.500 cm
Package 1 Length	19.000 cm
Package 1 Weight	990.000 g
Unit Type of Package 2	P06
Number of Units in Package 2	24
Package 2 Height	75.000 cm
Package 2 Width	60.000 cm
Package 2 Length	80.000 cm
Package 2 Weight	32.500 kg

Contractual warranty

Warranty	18 months
----------	-----------



Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing "Use Better, Use Longer, Use Again" campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Use Better

Materials and Substances

Packaging made with recycled cardboard	No
Packaging without single use plastic	No
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov


Use Again

Repack and remanufacture

Take-back	No
-----------	----

Dimensions Drawings

Dimensions

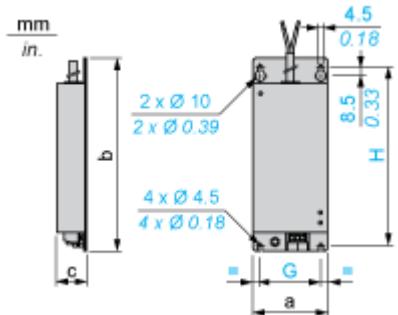

Dimensions in mm

a	b	c	G	H
117	184	40	97	170

Dimensions in in.

a	b	c	G	H
4.61	7.24	1.57	3.82	6.69