

Product data sheet

Specifications



Hand-held remote control, Harmony Pocket Remote, 3 single-step push buttons

ZART03

Product availability: Non-Stock - Not normally stocked in distribution facility

Main

Range of Product	Harmony Pocket Remote
Product or Component Type	Hand-held remote control
Device short name	ZART
Control Button Type	3 single step push-button

Complementary

Material	Push-button cover silicone rubber Enclosure ABS + PET
Function Available	Power switch
Display type	1 LED
Operating Distance	50 m
Communication network type	Wireless
Transmission frequency	2.4 GHz
Maximum sensing distance	984.3 ft (300 m) in free field
Response time	< 500 ms
Autonomy	> 100 h with alkaline batteries
Battery type	2 AAA/LR3 alkaline
Width	2.6 in (66 mm)
Height	4.5 in (114 mm)
Depth	1.5 in (37.5 mm)
Product Weight	0.298 lb(US) (0.135 kg)

Environment

Radio agreement	IC FCC
IP degree of protection	IP67
Ambient Air Temperature for Operation	-4...131 °F (-20...55 °C)
Ambient Air Temperature for Storage	-4...113 °F (-20...45 °C)
Operating altitude	0...6561.68 ft (0...2000 m)
Storage altitude	0...9842.5 ft (0...3000 m)
Relative humidity	0...95 % -4...140 °F (-20...60 °C) operating
Product Certifications	CE

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Ordering and shipping details

Category	US10CS222467
Discount Schedule	0CS2
GTIN	3606481499455
Returnability	Yes
Country of origin	CN

Packing Units

Unit Type of Package 1	PCE
Nbr. of units in pkg.	1
Package 1 Height	1.77 in (4.500 cm)
Package 1 Width	2.95 in (7.500 cm)
Package 1 Length	5.31 in (13.500 cm)
Package weight(Lbs)	6.279 oz (178.000 g)
Unit Type of Package 2	S01
Number of Units in Package 2	8
Package 2 Height	5.91 in (15.000 cm)
Package 2 Width	5.91 in (15.000 cm)
Package 2 Length	15.75 in (40.000 cm)
Package 2 Weight	3.611 lb(US) (1.638 kg)

Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint	
Carbon footprint (kg CO2 eq, Total Life cycle)	6
Environmental Disclosure	Product Environmental Profile

Use Better


Materials and Substances	
Packaging made with recycled cardboard	Yes
Packaging without single use plastic	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
SCIP Number	6e438e59-42d1-4633-bfe2-cb5ef607659b
California proposition 65	WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Use Again

Repack and remanufacture	
Circularity Profile	End of Life Information
Take-back	No
WEEE Label	 The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.


Dimensions Drawings

Transmitter Dimensions

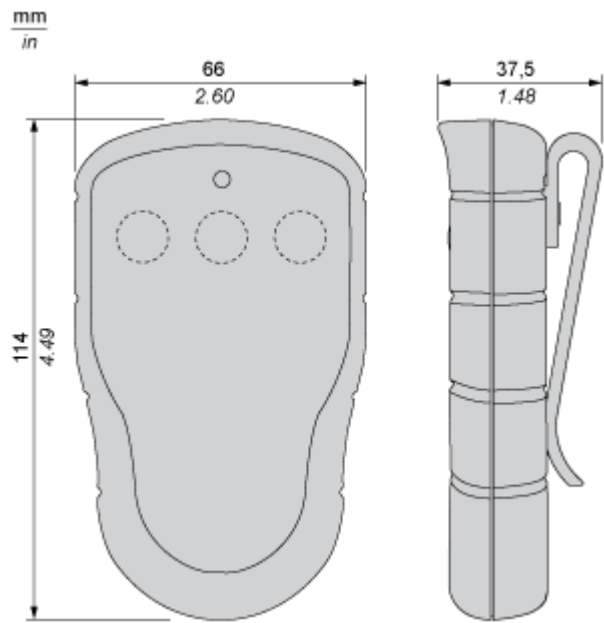

Technical Illustration

Dimensions

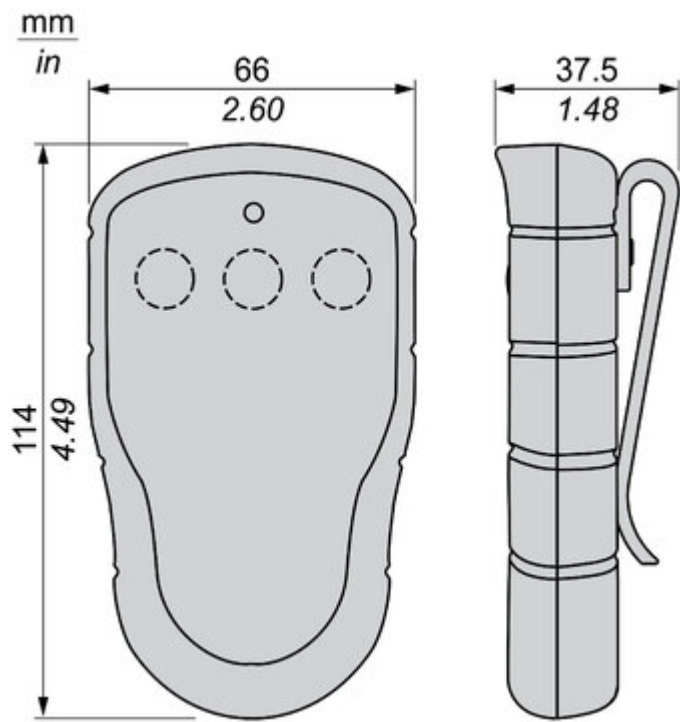

Offer Marketing Illustration

Product benefits / Features

Features

ZAR Harmony Pocket remote

Offers mobility solutions to improve operator efficiency and reduce installation time

Large set of colors and pictures to customize the front face of your pocket

Suitable for controlling all kinds of machines

Battery life: > 100 h with alkaline batteries

Relative humidity 0...95% to -20...55°C operation

Offer Marketing Illustration

Product benefits / Features

Technical benefits

ZAR Harmony Pocket remote

