

Product data sheet

Specifications



Socket-outlet, X Series, 20A, decorator, GFCI, tamper resistant, commercial, black, matte finish

SQR51201BK

Product availability: Stock - Normally stocked in distribution facility

Main

Range	Square D X Series
Product or Component Type	Socket-outlet
Aesthetic name	X Series
Device Application	Power supply
Device presentation	Mechanism with fixing frame
Body type	Decorator
Socket number	2
Outlet poles configuration	2P + E
Outlet standard	NEMA
Socket additional information	Tamper resistant

Complementary

Device mounting	Flush
Mounting Mode	By screws
[Ie] rated operational current AC	20 A
[Ue] rated operational voltage	125 V
Network type	AC
Network Frequency	60 Hz
Number of gangs	1 gang
Number of modules	1
Color	Black
surface treatment	Painted
Surface Finish	Matte
Material	Plastic: strap Metal: fixing frame
Connections - terminals	Phase and neutral 4 screw terminal copper Earth 1 screw terminal copper
Earth circuit	Self earthing
Protection Type	GFCI
Width	1.7 in (42 mm)
Height	4.06 in (103 mm)
Depth	1.6 in (41 mm)

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Quantity per Set	1 piece
------------------	---------

Environment

Product Certifications	cULus
Standards	UL 498 UL 943 ICES-003

Ordering and shipping details

Category	US10DE909932
Discount Schedule	0DE9
GTIN	785901544777
Returnability	Yes
Country of origin	CN

Packing Units

Unit Type of Package 1	PCE
Nbr. of units in pkg.	1
Package 1 Height	4.33 in (11.0 cm)
Package 1 Width	1.77 in (4.5 cm)
Package 1 Length	1.97 in (5.0 cm)
Package weight(Lbs)	4.8 oz (136.0 g)
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Height	4.72 in (12.0 cm)
Package 2 Width	4.13 in (10.5 cm)
Package 2 Length	9.25 in (23.5 cm)
Package 2 Weight	3.228 lb(US) (1.464 kg)
Unit Type of Package 3	PAL
Number of Units in Package 3	2520
Package 3 Height	47.24 in (120.0 cm)
Package 3 Width	39.37 in (100.0 cm)
Package 3 Length	47.24 in (120.0 cm)
Package 3 Weight	1003.72 lb(US) (455.28 kg)

Contractual warranty

Warranty	2 years
----------	---------

Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint	
Environmental Disclosure	Product Environmental Profile

Use Better

Materials and Substances	
Packaging made with recycled cardboard	Yes
Packaging without single use plastic	Yes
EU RoHS Directive	Compliant
REACH Regulation	REACH Declaration
California proposition 65	WARNING: This product can expose you to chemicals including: carbon black, which is known to the State of California to cause cancer, and Bisphenol A (BPA), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Use Again

Repack and remanufacture	
Circularity Profile	End of Life Information
Take-back	No

Technical Illustration

Wiring diagram

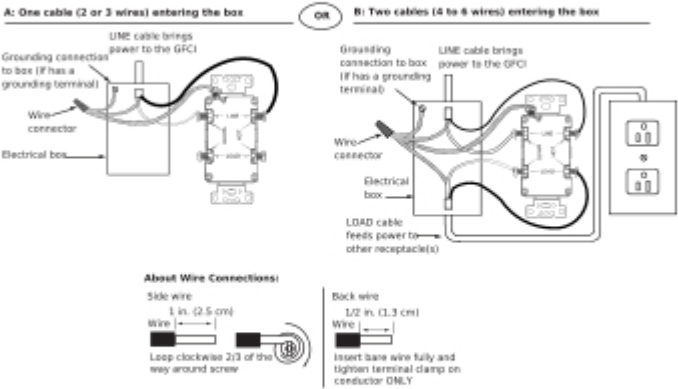


Image of product / Alternate images

Alternative

