

Product data sheet

Specifications



Empty handy box for mobile use,
Harmony XB5R, plastic, green, 2 cut
outs

ZBRM22

Product availability: Stock - Normally stocked in distribution
facility

Main

| | |
|-----------------------------|--------------------------------|
| Range of Product | Harmony XB5R |
| Product or Component Type | Empty handy box |
| Device short name | ZBRM |
| Product destination | For XB5R Ø 22 mm control units |
| Control station application | Two functions |

Complementary

| | |
|-----------------------------|-----------------------|
| Colour of base of enclosure | Green Pantone 355C) |
| Colour of cover | Dark grey RAL 7016) |
| Material | Polycarbonate |
| Product Weight | 0.24 lb(US) (0.11 kg) |

Environment

| | |
|---------------------------------------|--|
| Ambient Air Temperature for Storage | -40...158 °F (-40...70 °C) |
| Ambient Air Temperature for Operation | -13...131 °F (-25...55 °C) |
| IP degree of protection | IP65 IEC 60529 |
| IK degree of protection | IK03 conforming to IEC 62262 |
| Standards | ETSI EN 301 489-3 ETSI EN 301 489-1 ETSI EN 300 440-2 UL 508 CSA C22.2 No 14 ETSI EN 300 440-1 IEC 60947-5-1 |
| Product Certifications | FCC C-tick CE ANATEL SRRC BT 2006/95/EC GOST RSS |
| Directives | 1999/5/EC - R&TTE directive 2004/108/EC - electromagnetic compatibility |

Ordering and shipping details

| | |
|-------------------|--------------|
| Category | US1000I22470 |
| Discount Schedule | 000I |

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

| | |
|-------------------|---------------|
| GTIN | 3606480673542 |
| Returnability | Yes |
| Country of origin | HU |

Packing Units

| | |
|------------------------------|--------------------------|
| Unit Type of Package 1 | PCE |
| Nbr. of units in pkg. | 1 |
| Package 1 Height | 2.52 in (6.4 cm) |
| Package 1 Width | 2.68 in (6.8 cm) |
| Package 1 Length | 6.61 in (16.8 cm) |
| Package weight(Lbs) | 5.04 oz (143 g) |
| Unit Type of Package 2 | S03 |
| Number of Units in Package 2 | 32 |
| Package 2 Height | 11.81 in (30 cm) |
| Package 2 Width | 11.81 in (30 cm) |
| Package 2 Length | 15.75 in (40 cm) |
| Package 2 Weight | 11.257 lb(US) (5.106 kg) |
| Unit Type of Package 3 | P06 |
| Number of Units in Package 3 | 256 |
| Package 3 Height | 29.53 in (75 cm) |
| Package 3 Width | 23.62 in (60 cm) |
| Package 3 Length | 31.50 in (80 cm) |
| Package 3 Weight | 104.59 lb(US) (47.44 kg) |



Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint

Carbon footprint (kg CO₂ eq, Total Life cycle)

1

Use Better

Materials and Substances

Packaging made with recycled cardboard

No

Packaging without single use plastic

No

[EU RoHS Directive](#)

Pro-active compliance (Product out of EU RoHS legal scope)

SCIP Number

25b7f895-3732-43c8-9910-ef6005058640

California proposition 65

WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Use Again

Repack and remanufacture

Circularity Profile

[End of Life Information](#)

Take-back


No

Dimensions Drawings

Dimensions


Wireless and Batteryless Pushbutton

Plastic Mobile Box for Mobile or Fix Use - 2 Functions

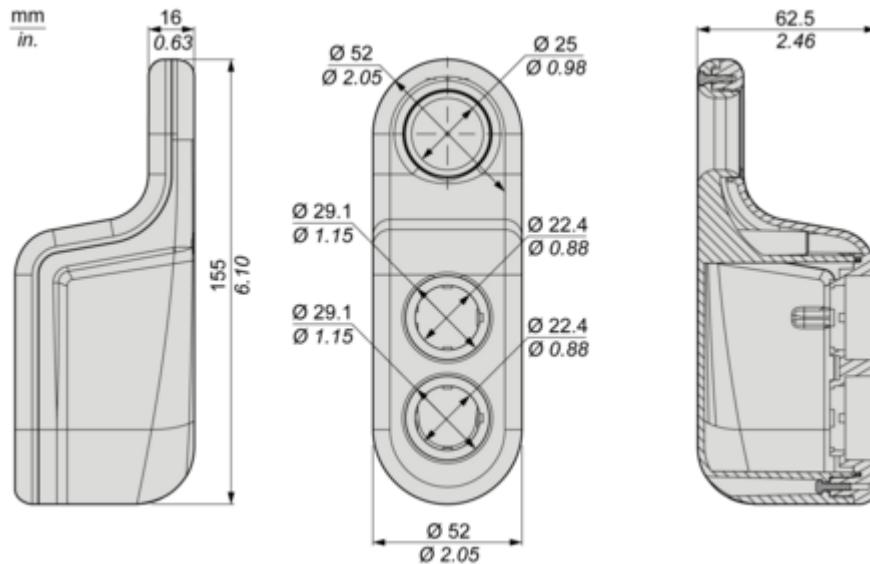

Technical Illustration

Dimensions

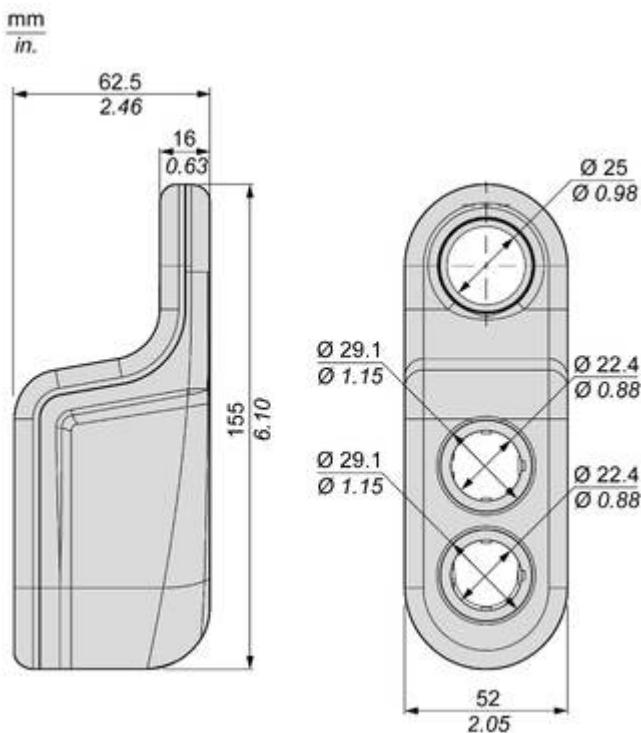

Offer Marketing Illustration

Product benefits / Features

Technical Benefits

Harmony XB5

Conformity with IEC, UL, CSA, CCC EAC, and JIS standards, as well as CE marking and marine approvals



Operating temperature from -40°C to 70°C

Up to IP66, 67, 69, 69K, and type 4X protection ratings



Shock protection level up to IK06

High vibration resistance with shake-proof terminal screws

Secure switching of inductive or heavy DC loads directly – 100 000 operations at 10A, 24V dc

Image of product / Alternate images

Alternative





