

Product data sheet

Specifications



Socket-outlet, X Series, 15A, decorator, GFCI, tamper resistant, residential, white, matte finish

SQR51101WH

Product availability: Stock - Normally stocked in distribution facility

Main

Range	Square D X Series
Product or Component Type	Socket-outlet
Aesthetic name	X Series
Device Application	Power supply
Device presentation	Mechanism with fixing frame
Body type	Decorator
Socket number	2
Outlet poles configuration	2P + E
Outlet standard	NEMA
Socket additional information	Tamper resistant

Complementary

Device mounting	Flush
Mounting Mode	By screws
[Ie] rated operational current AC	15 A
[Ue] rated operational voltage	125 V
Network type	AC
Network Frequency	60 Hz
Number of gangs	1 gang
Number of modules	1
Color	White
Surface Finish	Matte
Material	Plastic: strap Metal: fixing frame
Connections - terminals	Phase and neutral 4 screw terminal copper Earth 1 screw terminal copper
Earth circuit	Self earthing
Protection Type	GFCI
Width	1.7 in (42 mm)
Height	4.06 in (103 mm)
Depth	1.6 in (41 mm)
Quantity per Set	1 piece

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Environment

Product Certifications	cULus
Standards	UL 498 UL 943 ICES-003

Ordering and shipping details

Category	US10DE909932
Discount Schedule	ODE9
GTIN	00785901544562
Returnability	Yes
Country of origin	CN

Packing Units

Unit Type of Package 1	PCE
Nbr. of units in pkg.	1
Package 1 Height	1.90 in (4.826 cm)
Package 1 Width	2.10 in (5.334 cm)
Package 1 Length	4.40 in (11.176 cm)
Package weight(Lbs)	5.760 oz (163.293 g)
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Height	4.00 in (10.160 cm)
Package 2 Width	4.60 in (11.684 cm)
Package 2 Length	10.30 in (26.162 cm)
Package 2 Weight	3.790 lb(US) (1.719 kg)
Unit Type of Package 3	CAR
Number of Units in Package 3	60
Package 3 Height	11.00 in (27.940 cm)
Package 3 Width	7.20 in (18.288 cm)
Package 3 Length	17.80 in (45.212 cm)
Package 3 Weight	22.000 lb(US) (9.979 kg)

Contractual warranty

Warranty	2 years
----------	---------



Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint

Carbon footprint (kg CO₂ eq, Total Life cycle) **90**

Environmental Disclosure [Product Environmental Profile](#)

Use Better

Materials and Substances

Packaging made with recycled cardboard **Yes**

Packaging without single use plastic **No**

[EU RoHS Directive](#) **Compliant with Exemptions**

REACH Regulation [REACH Declaration](#)

California proposition 65
WARNING: This product can expose you to chemicals including: carbon black, which is known to the State of California to cause cancer, and Bisphenol A (BPA), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Use Again

Repack and remanufacture

Circularity Profile [No need of specific recycling operations](#)

Take-back **No**

Technical Illustration

Wiring diagram

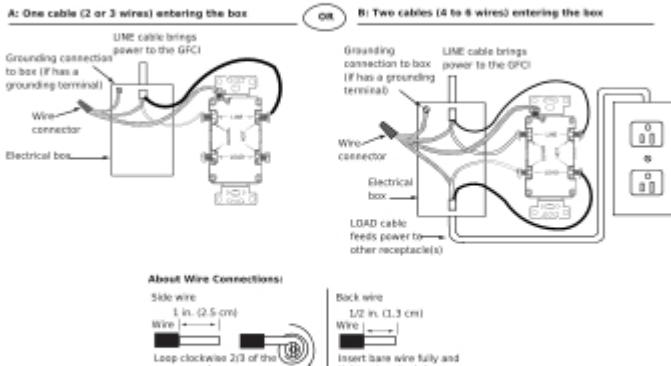


Image of product / Alternate images

Alternative

