

Product data sheet

Specifications



Rotating beacon, Harmony XVR,
120mm, orange, with buzzer 50...
90dB, 24V AC DC

XVR12B05S

Product availability: Non-Stock - Not normally stocked in distribution facility

Main

| | |
|---------------------------|------------------------------------------------|
| Range of Product | Harmony XVR |
| Product or Component Type | Prewired rotating mirror beacon |
| Sound signalling | Buzzer |
| Device short name | XVR |
| Mounting diameter | 4.7 in (120 mm) |
| IP degree of protection | IP23 IEC 60529 |
| [Us] rated supply voltage | 24 V AC/DC |
| Light source | High luminosity LED, orange |
| Noise level | 50...90 dB continuous or intermittent tone)1 m |

Complementary

| | |
|----------------------------------------|---------------------------------------------------------------|
| Material | ABS (acrylonitrile butadiene-styrene): body part AS: globe |
| CAD overall width | 4.7 in (120 mm) |
| CAD overall depth | 4.7 in (120 mm) |
| Product Weight | 1.1 lb(US) (0.5 kg) |
| Marking | CE |
| Product mounting | By 3 M5 screws |
| Supply voltage limits | 19...30 V DC 21.6...26.4 V AC |
| [Uimp] rated impulse withstand voltage | 0.8 kV |
| Current Consumption | 196 mA |
| Flashing frequency | 2.3 Hz |
| Clamping Connection Capacity | 0.83 mm ² |
| AWG Gauge | AWG 18 |
| Cable length | 15.7 in (400 mm) |

Environment

| | |
|-------------------------------------|--------------------------------|
| Standards | IEC 61000-6-4 IEC 61000-6-2 |
| Protective treatment | TC |
| Ambient Air Temperature for Storage | -31...158 °F (-35...70 °C) |

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Ambient Air Temperature for Operation 14...122 °F (-10...50 °C)

Electrical shock protection class Class II IEC 61140

Ordering and shipping details

Category US100XV22617

Discount Schedule 00XV

GTIN 3606480033247

Returnability Yes

Country of origin ID

Packing Units

Unit Type of Package 1 PCE

Nbr. of units in pkg. 1

Package 1 Height 5.43 in (13.800 cm)

Package 1 Width 5.43 in (13.800 cm)

Package 1 Length 7.68 in (19.500 cm)

Package weight(Lbs) 23.245 oz (659.000 g)

Unit Type of Package 2 S04

Number of Units in Package 2 8

Package 2 Height 11.81 in (30.000 cm)

Package 2 Width 15.75 in (40.000 cm)

Package 2 Length 23.62 in (60.000 cm)

Package 2 Weight 14.570 lb(US) (6.609 kg)

Contractual warranty

Warranty 18 months



Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint

Carbon footprint (kg CO2 eq, Total Life cycle) **82**

Environmental Disclosure [Product Environmental Profile](#)

Use Better

Materials and Substances

Packaging made with recycled cardboard **Yes**

Packaging without single use plastic **No**

[EU RoHS Directive](#) **Pro-active compliance (Product out of EU RoHS legal scope)**

California proposition 65 **WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](#)**

Use Again

Repack and remanufacture



Circularity Profile [End of Life Information](#)

Take-back **No**

Dimensions Drawings

Rotating Mirror Beacon


Dimensions

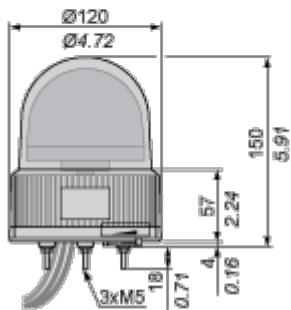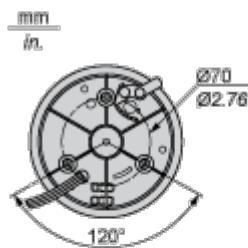

Mounting and Clearance

Rotating Mirror Beacon

Panel Cut-out

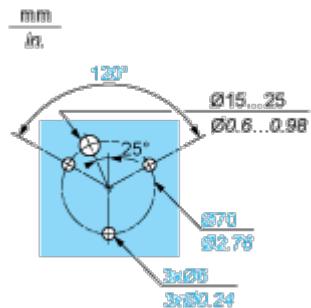

Technical Illustration

Dimensions

