


Product data sheet

Characteristics

XAPG39704SBP

22mm push button, Harmony XALD, empty grey enclosure, die cast zinc alloy, 4 openings, horizontal mount, NEMA 4, 13

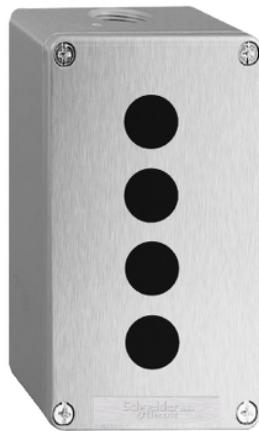

Main

Range of Product	Harmony XAP
Product or Component Type	Die-cast empty control station
Device short name	XAPG
Product destination	For Ø 22 mm control and signalling units
Number of cut-out	4 cut-outs
Colour of base of enclosure	Grey RAL 7032)
Colour of cover	Grey RAL 7032)
Control station type	Metal
Material	Die cast zinc
Sale per indivisible quantity	1
IP degree of protection	IP65 IEC 60529 IP657 NF C 20-010
Resistance to chemical agents	Special treatment can be obtained on request

Complementary

Number of vertical rows	1
Number of horizontal rows	4
Cut-out dimensions	Ø 22 mm
Cable entry	Cable gland 1 x cable gland
Thread type	3/4 NPT
CAD overall width	3.15 in (80 mm)
CAD overall height	6.89 in (175 mm)
CAD overall depth	2.03 in (51.5 mm)
Net Weight	1.90 lb(US) (0.860 kg)
Compatibility code	XAPG

Environment

Protective treatment	TH
Ambient Air Temperature for Storage	-40...158 °F (-40...70 °C)
Ambient Air Temperature for Operation	-13...158 °F (-25...70 °C)
Electrical shock protection class	Class I IEC 60536 Class I NF C 20-030
IK degree of protection	IK07 EN/IEC 62262

Ordering and shipping details

Category	22468-PUSHBUTTONS,22MM(METAL) NEW
Discount Schedule	CS2
GTIN	3389119082235
Returnability	No
Country of origin	FR

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	4.72 in (12.0 cm)
Package 1 Width	3.46 in (8.8 cm)
Package 1 Length	7.28 in (18.5 cm)
Package 1 Weight	2.82 lb(US) (1.28 kg)

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	 REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)  EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	 China RoHS Declaration
RoHS exemption information	 Yes
Environmental Disclosure	 Product Environmental Profile