

# Product data sheet

Specifications



Light block, Harmony 9001K,  
Harmony 9001SK, 30mm,  
incandescent bulb, 120V

9001KM38

Product availability: Non-Stock - Not normally stocked in distribution facility

## Main

Range of Product	Harmony 9001K Harmony 9001SK
Product or Component Type	Light block
Device short name	9001K
Bulb base	BA 9s
Light block supply	Direct via integral resistance

## Complementary

Net Weight	0.11 lb(US) (0.05 kg)
Light source	Incandescent bulb
[Us] rated supply voltage	120 V AC/DC
[Us] rated supply voltage	120 V
Light block supply	Full voltage or resistor
Size	30 mm

## Environment

Protective treatment	TC
Ambient Air Temperature for Storage	-40...158 °F (-40...70 °C)
Ambient Air Temperature for Operation	-13...158 °F (-25...70 °C)
IP degree of protection	IP20 IEC 60529
Standards	IEC 60947-5-1 UL 508 IEC 60947-5-4 IEC 60947-1 CSA C22.2 No 14 JIS C 852 JIS C 4520
Product Certifications	NEMA UL 508
Electrical shock protection class	Class II conforming to IEC 61140
Vibration resistance	7 gn (f= 2...500 Hz) conforming to IEC 60068-2-6
Shock resistance	50 gn IEC 60068-2-27

## Ordering and shipping details

Category	US10CS121435
----------	--------------

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Discount Schedule	0CS1
GTIN	3389110918557
Returnability	Yes
Country of origin	MX

## Packing Units

Unit Type of Package 1	PCE
Nbr. of units in pkg.	1
Package 1 Height	2.20 in (5.588 cm)
Package 1 Width	3.70 in (9.398 cm)
Package 1 Length	2.00 in (5.080 cm)
Package weight(Lbs)	2.240 oz (63.500 g)
Unit Type of Package 2	S03
Number of Units in Package 2	50
Package 2 Height	11.81 in (30.000 cm)
Package 2 Width	11.81 in (30.000 cm)
Package 2 Length	15.75 in (40.000 cm)
Package 2 Weight	9.083 lb(US) (4.120 kg)
Unit Type of Package 3	P06
Number of Units in Package 3	400
Package 3 Height	29.53 in (75.000 cm)
Package 3 Width	31.50 in (80.000 cm)
Package 3 Length	23.62 in (60.000 cm)
Package 3 Weight	90.301 lb(US) (40.960 kg)

## Contractual warranty

Warranty	18 months
----------	-----------



## Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

### Use Better

#### Materials and Substances

Packaging made with recycled cardboard	Yes
Packaging without single use plastic	Yes
<a href="#">EU RoHS Directive</a>	Pro-active compliance (Product out of EU RoHS legal scope)
SCIP Number	Ae0c4eb9-0bfb-40a4-851f-5c619fbe777d
REACH Regulation	<a href="#">REACH Declaration</a>
California proposition 65	<b>WARNING:</b> This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="#">www.P65Warnings.ca.gov</a>


### Use Again

#### Repack and remanufacture

Take-back	No
WEEE Label	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

## Dimensions Drawings

## Dimensions

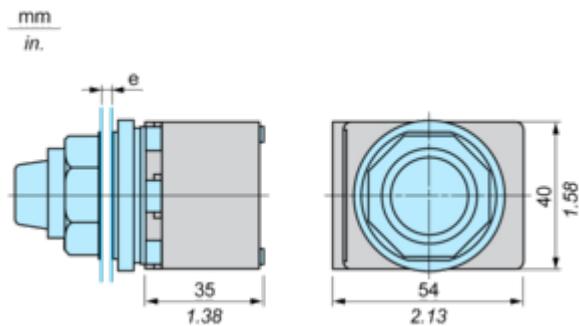

e panel thickness: 1 to 6 mm / 0.04 to 0.24 in.

## Offer Marketing Illustration

### Product benefits / Features

### Features

#### Harmony 9001K



- 

Improved security thanks to finger-safe contact blocks and light modules
- 

Single screw Contact Block Fastening
- 

Robustness to withstand the harshest environments
- 

Large metal set of accessories to customize your product
- 

Automatic self-grounding operators without additional wiring

## Offer Marketing Illustration

## Product benefits / Features

## Technical Benefits

## Harmony 9001K



Image of product in real life situation

