


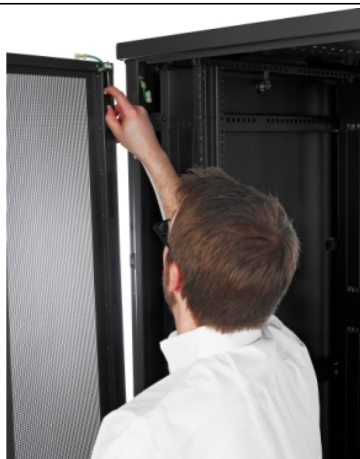

Overview

Presentation	Universal IT enclosure provided with no side panels for spaces that require less security at the rack or will be paired with other enclosures to form a row and position side panels only at the row ends. The enclosure is for low to medium density server and networking applications. Compact width to optimize data center space. 42U height to easily roll through doorways.
Lead time	Usually in Stock

Main

Number of rack unit	42U
Provided equipment	Baying hardware Door key Doors Leveling feet Mounting Hardware Pre-installed casters 4 x Bolt down brackets Roof Unpacking sheet

Physical

Color	Black
Height	80.98 in (205.7 cm)
Width	23.62 in (60 cm)
Depth	41.73 in (106 cm)
Net Weight	187.39 lb(US) (85 kg)
Mounting preference	No preference
Mounting Mode	Not rack-mountable
Maximum Mounting Depth	30.60 in (77.72 cm)
Minimum Mounting Depth	6.60 in (16.76 cm)
Rack Width	19"
Marking	15 gauge EIA mounting rail 16 gauge front door 18 gauge post 16 gauge rear door 19 gauge roof 18 gauge side panels
Permanent permissible load	1014 Lb(US) (459.94 kg) dynamic 2205 lb(US) (1000.17 kg) static

Conformance

Standards	UL 2416 UL 60950-1 EIA-310E
-----------	-----------------------------------

Ordering and shipping details

GTIN	731304302056
Package weight(Lbs)	225.53 lb(US) (102.3 kg)

Packing Units

Package 1 Height	85.87 in (218.1 cm)
Package 1 width	27.56 in (70 cm)
Package 1 Length	45.67 in (116 cm)

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	 REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)  EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	 Yes
Take-back	Take-back program available

Contractual warranty

Warranty	5 year repair or replace
----------	--------------------------