

Product data sheet

Specifications



Safety switch, VisiPacT, heavy duty, unfused, viewing window, NEMA 12, 600V, 200A, 3 pole, ground lugs

VHU364AWKGL

Product availability: Stock - Normally stocked in distribution facility

Main

Product	Single Throw Safety Switch
Duty Rating	Heavy duty
Device Application	Heavy application
Disconnect Type	Non-fusible disconnect
Factory Installed Neutral	Field installed kit available
Number of Poles	3
Current Rating	200 A
Voltage Rating	600 V AC/DC
Enclosure Rating	NEMA 12 galvanized steel
Standard Motor Power Rating	15 hp at 240 V AC 50/60 Hz for 1 phase motors 60 hp at 240 V AC 50/60 Hz for 3 phase motors 50 hp at 480 V AC 50/60 Hz for 1 phase motors 125 hp at 480 V AC 50/60 Hz for 3 phase motors 50 hp at 600 V AC 50/60 Hz for 1 phase motors 150 hp at 600 V AC 50/60 Hz for 3 phase motors 40 hp at 250 V DC 50 hp at 600 V DC

Complementary

Mounting Type	Surface
Electrical Connection	Lugs
Wiring configuration	3-wire
Wire Size	AWG 6...250 kcmil copper or aluminium
Tightening torque	275 lbf.in (31.07 N.m) 0.02...0.2 in² (13.3...127 mm²) (AWG 6...250 kcmil)
Depth	9.02 in (229.11 mm)
Width	17.01 in (432.05 mm)
Height	28.93 in (734.82 mm)
Net Weight	52.007 lb(US) (23.59 kg)
Grounding Kit	Factory installation
Service Entrance	Suitable service entrance for USA Suitable service entrance for Mexico

Environment

Certifications	UL listed file E2875
----------------	----------------------

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Standards	UL98 CSA C22.2 No 4 NOM-003-SCFI-2000
-----------	---

Ordering and shipping details

Category	US10DE100113
Discount Schedule	0DE1
GTIN	3606485894959
Returnability	Yes
Country of origin	US

Packing Units

Unit Type of Package 1	PCE
Nbr. of units in pkg.	1
Package 1 Height	9.72 in (24.700 cm)
Package 1 Width	19.80 in (50.300 cm)
Package 1 Length	32.83 in (83.400 cm)
Package weight(Lbs)	54.600 lb(US) (24.766 kg)

Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint	
Carbon footprint (kg CO2 eq, Total Life cycle)	274
Environmental Disclosure	Product Environmental Profile

Use Better


Materials and Substances	
Packaging made with recycled cardboard	Yes
Packaging without single use plastic	Yes
EU RoHS Directive	Compliant
REACH Regulation	REACH Declaration
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Use Again

Repack and remanufacture	
Circularity Profile	No need of specific recycling operations
Take-back	No
WEEE Label	 The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

Technical Illustration


Dimensions

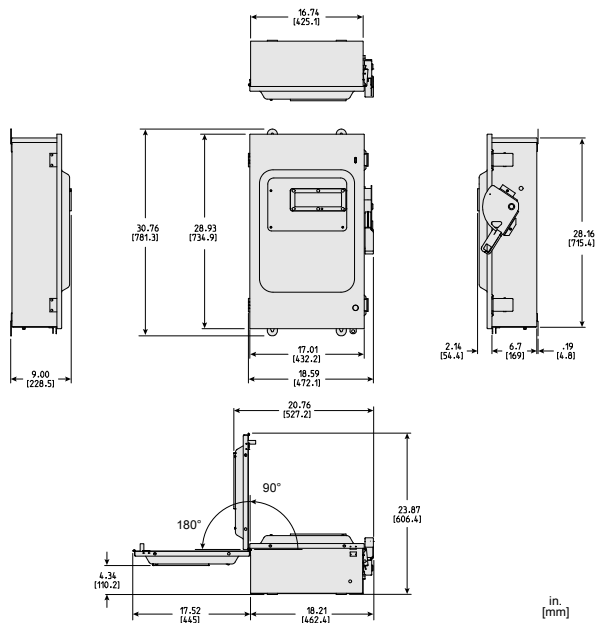

ALL DIMENSIONS ARE APPROXIMATE.
REFER TO TECHNICAL DRAWINGS AND DOCUMENTATION FOR COMPLETE INFORMATION.

Technical Illustration

Wiring diagram

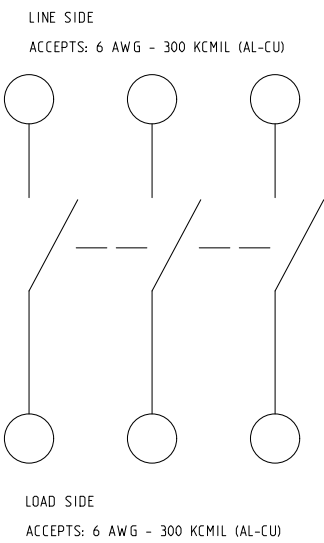

CATALOG NO. VHU364AWKGL
REFER TO TECHNICAL DRAWINGS AND DOCUMENTATION FOR COMPLETE INFORMATION.