

Product data sheet

Specifications



Wall mounted enclosure, PanelSeT S3X, stainless steel 316L, plain door, 600x600x250mm, IP66

NSYS3X6625H

Product availability: Non-Stock - Not normally stocked in distribution facility

Main

Range	Spacial
Product name	Spacial S3X
enclosure type	Multi-purpose
category	Compact enclosure
nominal height	23.6 in (600 mm)
nominal width	23.6 in (600 mm)
nominal depth	9.8 in (250 mm)
product installation	Wall-mounting
Device composition	1 body 1 door 2 lock door 2 perforated vertical profile drilled door

Complementary

Body type	Single piece body, cross-shaped structure Gutter shaped front rail
Door type	Solid
Number of doors	Front face 1
Door opening side	Reversible 120 °)
Lock type	2 points lock, 3 mm double-bar
Mounting plate description	Without mounting plate
Type of gland plate	Without gland plate
Accessibility for operation	Front
Removable parts	Door by hinges
Material	Lock zamak Hinge stainless steel Body and door stainless steel 316L
Surface finish	Body and door Scotch-Brite® brushed Lock chromium plated
Product Weight	30.9 lb(US) (14 kg)

Environment

Standards	IEC 62208 UL CUL
-----------	------------------------

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Product Certifications	CAN/CSA 22 UL 508 type A
IP degree of protection	IP66 IEC 60529
IK degree of protection	IK10 IEC 62262
Environmental characteristic	Specific hygiene Corrosive

Ordering and shipping details

Category	US10ES180034
Discount Schedule	0ES1
GTIN	3606480155253
Returnability	No
Country of origin	BG

Packing Units

Unit Type of Package 1	PCE
Nbr. of units in pkg.	1
Package 1 Height	10.63 in (27.000 cm)
Package 1 Width	24.02 in (61.000 cm)
Package 1 Length	24.02 in (61.000 cm)
Package weight(Lbs)	30.865 lb(US) (14.000 kg)
Unit Type of Package 2	PAM
Number of Units in Package 2	18
Package 2 Height	78.74 in (200.000 cm)
Package 2 Width	39.37 in (100.000 cm)
Package 2 Length	47.24 in (120.000 cm)
Package 2 Weight	588.635 lb(US) (267.000 kg)

Contractual warranty

Coverage	Core product
Warranty	18 months

Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint	
Carbon footprint (kg CO2 eq, Total Life cycle)	208
Environmental Disclosure	Product Environmental Profile

Use Better


Materials and Substances	
Packaging made with recycled cardboard	No
Packaging without single use plastic	No
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
SCIP Number	E893f0a0-d2cc-4011-9425-3873dde70142
REACH Regulation	REACH Declaration

Use Again

Repack and remanufacture	
Circularity Profile	No need of specific recycling operations
Take-back	No

Technical Illustration

Dimensions

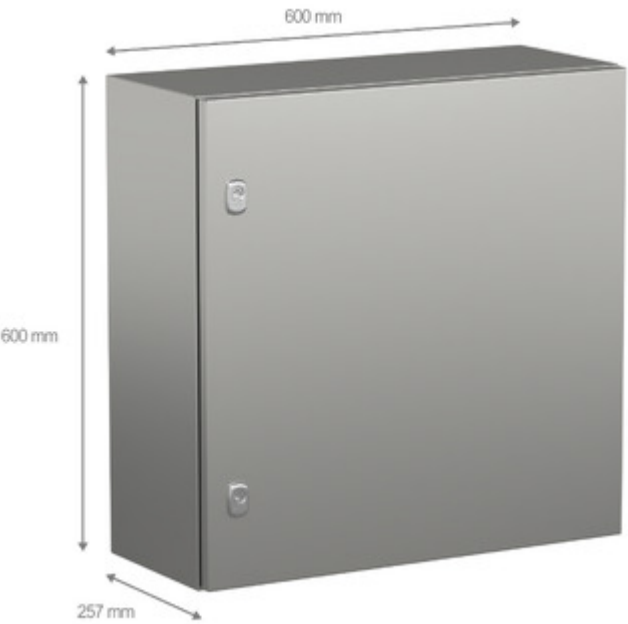

Offer Marketing Illustration

Product benefits / Features



High resistance
to corrosion



Earthing
studs included



Large choice
of dimensions
& accessories



Easy to equip
Easy to maintain





Easy & quick
assembly



Built
to last