


AR203A

NetShelter 4 Post Open Frame Rack 44U Square Holes

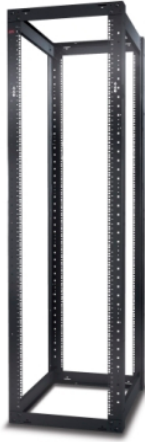

Overview

Lead time	Usually in Stock
-----------	------------------

Main

Number of rack unit	44U
Provided equipment	Installation guide

Physical

Color	Black
Height	83.86 in (213 cm)
Width	23.62 in (60 cm)
Depth	29.41 in (74.7 cm)
Net Weight	89.09 lb(US) (40.41 kg)
Mounting Location	Front Rear
Mounting preference	No preference
Mounting Mode	Not rack-mountable
Maximum Mounting Depth	29.13 in (73.99 cm)
Minimum Mounting Depth	29.13 in (73.99 cm)
Rack width	19"
Permanent permissible load	2000 lb(US) (907.18 kg) static

Conformance

Standards	EIA-310E
-----------	----------

Ordering and shipping details

GTIN	731304260233
------	--------------

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	82.01 in (208.3 cm)
Package 1 Width	4.45 in (11.3 cm)
Package 1 Length	10.00 in (25.4 cm)
Package 1 Weight	89.99 lb(US) (40.82 kg)

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	 REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)  EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	 Yes
Take-back	Take-back program available

Contractual warranty

Warranty	5 year repair or replace
----------	--------------------------