


Product data sheet

Specifications

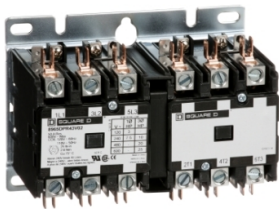

Reversing hoist contactor, 40A, 3 pole, 24VAC 50/60 Hz coil, open style

8965DPR43V14

Product availability: Stock - Normally stocked in distribution facility

Main

Product or Component Type	Reversing Hoist Contactor
Line Rated Current	40 A
Maximum Horse Power Rating	3 hp 115 V AC, 1 phase 7.5 hp 230 V AC, 1 phase 15 hp 230 V AC, 3 phase 20 hp 460 V AC, 3 phase 20 hp 575 V AC, 3 phase

Complementary

Product Certifications	UL Listed CSA
[Ue] rated operational voltage	600 V AC
Poles description	3P
[Uc] control circuit voltage	24 V AC 50/60 Hz
Phase	3 phase
Range of Product	DPR

Ordering and shipping details

Category	US10CP121403
Discount Schedule	0CP1
GTIN	785901571568
Returnability	Yes
Country of origin	CN

Packing Units

Unit Type of Package 1	PCE
Nbr. of units in pkg.	1
Package 1 Height	4.30 in (10.922 cm)
Package 1 Width	4.70 in (11.938 cm)
Package 1 Length	6.20 in (15.748 cm)
Package weight(Lbs)	2.381 lb(US) (1.080 kg)
Unit Type of Package 2	PAL
Number of Units in Package 2	300
Package 2 Height	48.00 in (121.920 cm)

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Package 2 Width	42.00 in (106.680 cm)
Package 2 Length	48.00 in (121.920 cm)
Package 2 Weight	476.0005 lb(US) (215.910 kg)

Contractual warranty

Warranty	18 months
----------	-----------

Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Use Better

 Materials and Substances	
Packaging made with recycled cardboard	Yes
Packaging without single use plastic	Yes
EU RoHS Directive	Compliant with Exemptions

Use Again

 Repack and remanufacture	
Take-back	No