



Mallory Sonalert Products, Inc.

Part #:

FAD101-22HRS

Sales Outline Drawing

Revision:

A

Specifications:

May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.

Meter Type	Hour-Minute Meter
Panel Hole	22 mm
Rated Voltage (VAC)	220-380 $\pm 20\%$
Timing Range	Minutes 0-60 / Hours 0-999
Sampling Rate	Approx. 1 time/sec
Display Resolution	1 minute
Brightness	≥ 100 cd/m ²
LED Colors	Blue, Green, Red, White, Yellow
Ingress Protection Rating	IP54
Max Nut Torque	1.0 N-m
Max Screw Torque	0.8 N-m
Max Wire Gauge for Screw Terminals	14 AWG
Operating Temperature	-25 °C to +55 °C
Insulation Resistance	$\geq 2\text{M}\Omega$
Max Wire Gauge for Current Loop	2.5mm ² (14AWG)
Prompt when no signal input	Display "0"
Device Power Loss	< 1VA

Part Number:




RoHS Compliant

FAD101-22HRS-*

* NOTES LED COLOR

B BLUE
G GREEN
R RED
W WHITE
Y YELLOW

Dimensions (mm):

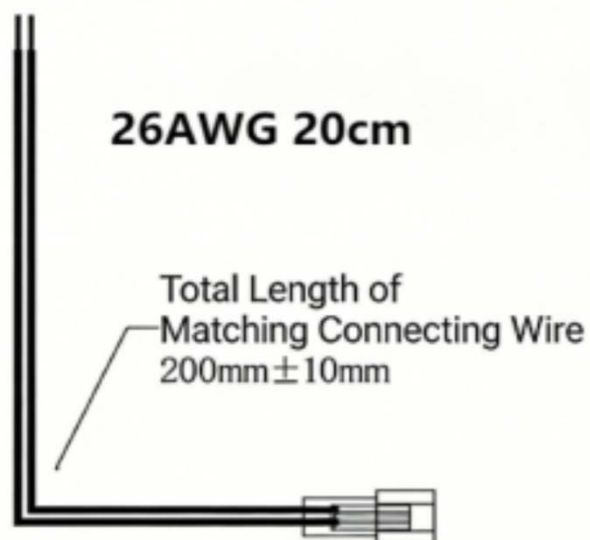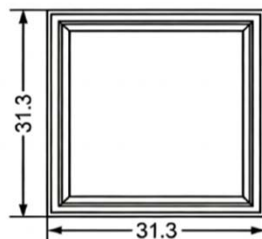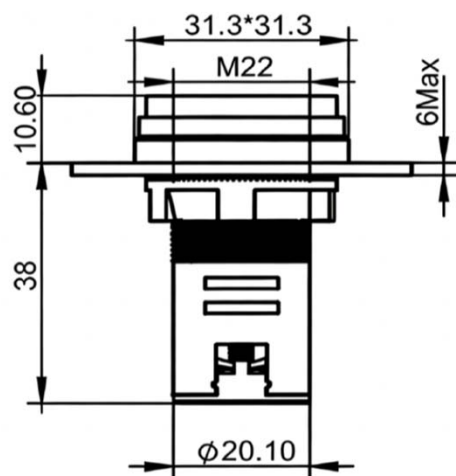

This product shall NOT be applied to circuits with variable or high frequency, inverter output or severe harmonic interference. Applicable only to pure sine wave 50/60 Hz standard AC Mains power supply.