



Mallory Sonalert Products, Inc.

Part #: **FAD101-22TMCS**

Sales Outline Drawing

Revision: **A**

Specifications:

May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.

Meter Type	Temperature Meter (C)
Panel Hole	22 mm
Rated Voltage (VAC)	50-380 $\pm 20\%$
Temperature Range	-20°C ~ 199°C
Brightness	≥ 100 cd/m ²
LED Colors	Blue, Green, Red, White, Yellow
Ingress Protection Rating	IP54
Max Nut Torque	1.0 N-m
Max Screw Torque	0.8 N-m
Max Wire Gauge for Screw Terminals	14 AWG
Operating Temperature	-25 °C to +65 °C
Insulation Resistance	$\geq 2\text{M}\Omega$
Max Wire Gauge for Current Loop	2.5mm ² (14AWG)
Prompt when no signal input	Display "000"
Device Power Loss	< 1VA

Part Number:


FAD101-22TMCS-*

RoHS Compliant

* NOTES LED COLOR

B BLUE
G GREEN
R RED
W WHITE
Y YELLOW

Dimensions (mm):

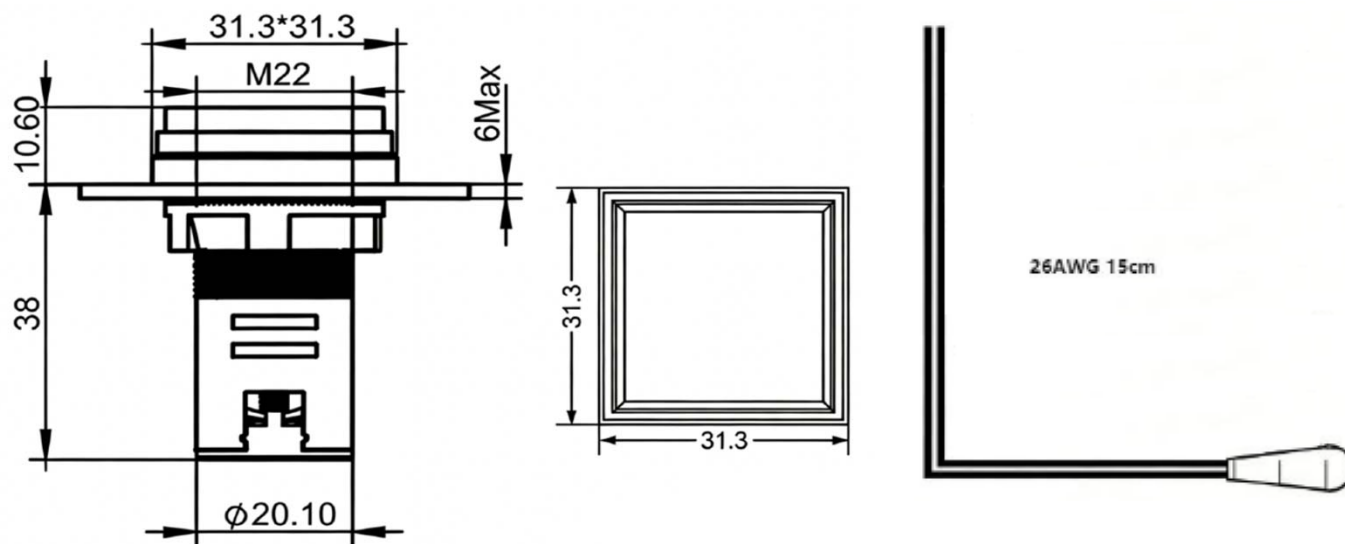

This product shall NOT be applied to circuits with variable or high frequency, inverter output or severe harmonic interference. Applicable only to pure sine wave 50/60 Hz standard AC Mains power supply.