

**Mallory Sonalert Products, Inc.**

Part #:

FAD101-22VMDS**Sales Outline Drawing**

Revision:

A**Specifications:**

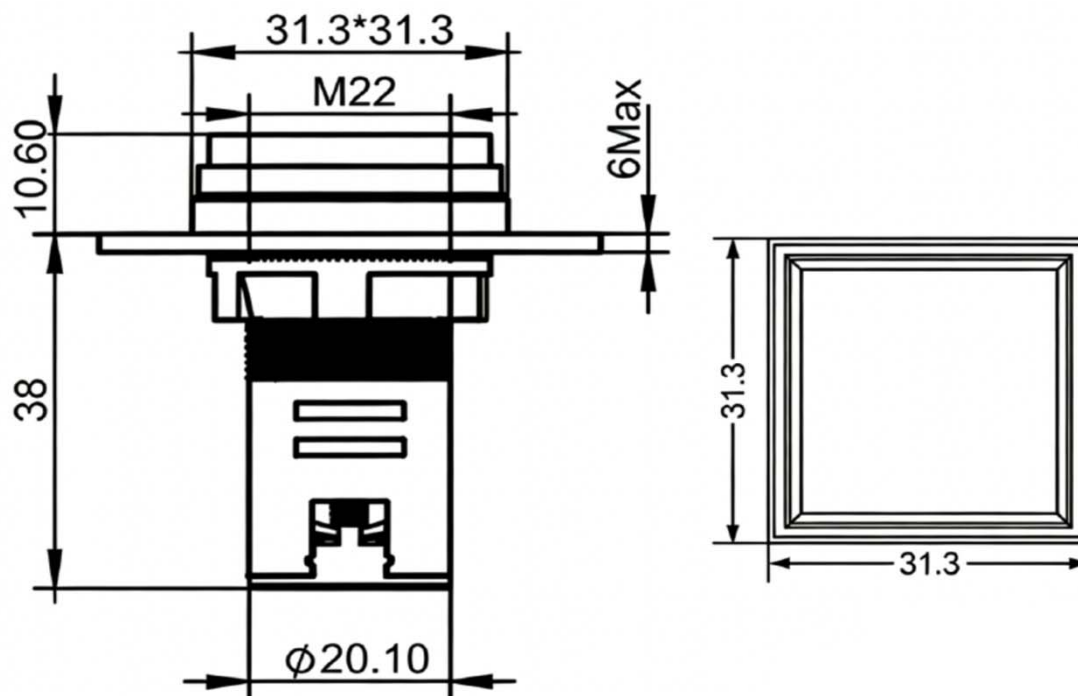
May not be suitable for all Medical and Aerospace applications.

Contact Mallory Sonalert to discuss your application.

Meter Type	Voltage Meter (VAC)
Panel Hole	22 mm
Rated Voltage (VDC)	5-60 $\pm 20\%$
Accuracy	$\pm 2\%$
Brightness	$\geq 100 \text{ cd/m}^2$
LED Colors	Blue, Green, Red, White, Yellow
Ingress Protection Rating	IP54
Max Nut Torque	1.0 N-m
Mas Screw Torque	0.8 N-m
Max Wire Gauge for Screw Terminals	14 AWG
Operating Temperature	-25 °C to +55 °C
Insulation Resistance	$\geq 2\text{M}\Omega$
Prompt when no signal input	Display "000"
Device Power Loss	< 1VA

Part Number:**RoHS Compliant****FAD101-22VMDS-****** NOTES LED COLOR**

B	BLUE
G	GREEN
R	RED
W	WHITE
Y	YELLOW

Dimensions (mm):

This product shall NOT be applied to circuits with variable or high frequency, inverter output or severe harmonic interference. Applicable only to pure sine wave 50/60 Hz standard AC Mains power supply.