



Mallory Sonalert Products, Inc.

Part #: **FPM12-FJ3-S0M4B12**

Sales Outline Drawing

Revision: **A**

Specifications:

May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.

Panel Hole	12 mm
Rated Voltage (VDC)	12
Rated Current (mA) DC	50
LED Color	Blue
Switch Function	OFF-MOM
Circuit	1NO
Storage & Operating Temperature	-25 °C to +85 °C
Ingress Protection Rating	IP67
Shock Resistance	IK08
Material, Base	PC
Material, Body	304 Stainless steel
Material, Button	304 Stainless steel
Material, Contact	Silver plated copper alloy
Termination Type	Solder Lug
Hardware Kit	LM12-FSQ12-MHDP12

RoHS Compliant




Part Number:

FPM12-FJ3-S0M4B12-*

* NOTES BUTTON COLOR

B	BLUE
BL	BLACK
G	GREEN
R	RED
W	WHITE
Y	YELLOW
BLANK	CLEAR

Dimensions (mm):

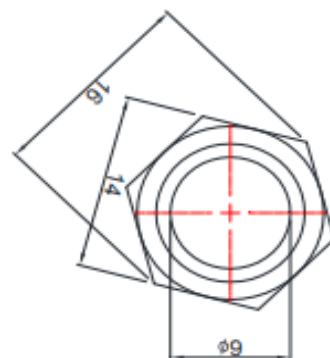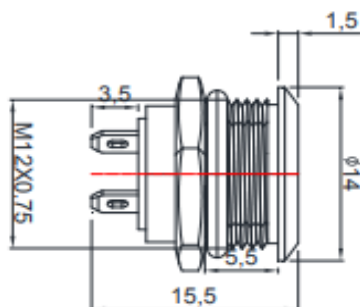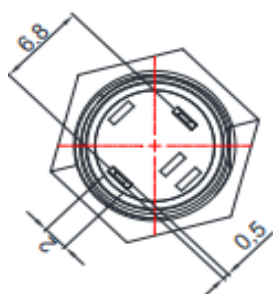

CONNECTION DIAGRAM:



PANEL HOLE:

