

**Mallory Sonalert Products, Inc.**Part #: **FPM12-HJ1-S0Z4B12****Sales Outline Drawing**Revision: **A****Specifications:**

May not be suitable for all Medical and Aerospace applications.

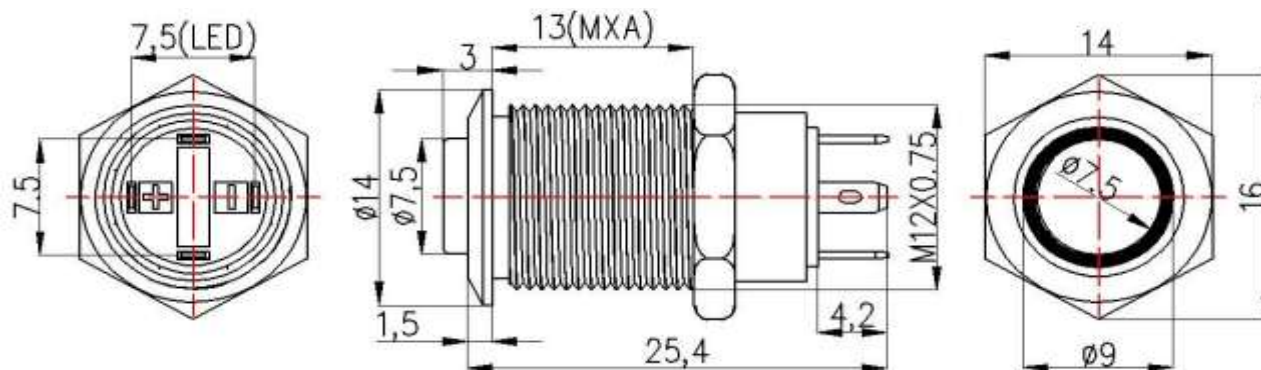
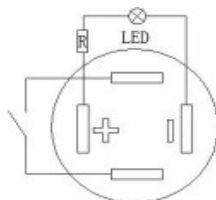
Contact Mallory Sonalert to discuss your application.

Panel Hole (mm)	12 mm
Switch Rated Voltage (VDC / VAC)	36 / 250
Switch Rated Current (A) DC / AC	2 / 1
LED Rated Voltage (VDC)	10.8-13.2
LED Rated Current (mA)	≤20
Button Color	Blue
Switch Function	OFF-ON
Circuit	SPST 1NO
Storage & Operating Temperature	-25 °C to +85 °C
Ingress Protection Rating	IP65
Shock Resistance	IK08
Certifications	UL, cUL listed under Series FLM19-FJ-1
Material	PC Plastic, PA66+GF20%, Stainless
Termination Type	Solder Lugs

RoHS Compliant**Part Number:****FPM12-HJ1-S0Z4B12***

* NOTES LED COLOR & VDC

R	RED
G	GREEN
B	BLUE
Y	YELLOW
W	WHITE
BLANK	CLEAR

Dimensions (mm):**CONNECTION DIAGRAM:****PANEL HOLE:**