



Mallory Sonalert Products, Inc.

Part #: **FPM19-FJ6-A0Z4B3**

Sales Outline Drawing

Revision: **A**

Specifications:

May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.

Panel Hole (mm)	19 mm
Switch Rated Voltage (VDC / VAC)	36 / 250
Switch Rated Current (A) DC / AC	20 / 20
LED Rated Voltage (VDC)	3.12-3.2
LED Rated Current (mA)	≤20
Button Color	Blue
Switch Function	OFF-ON
Circuit	SPST 1NO
Storage & Operating Temperature	-25 °C to +85 °C
Ingress Protection Rating	IP67
Shock Resistance	IK09
Material	PC Plastic, PA66+GF20%, Aluminum Alloy
Termination Type	Flat Blades-4.8mm

RoHS Compliant


Part Number:

FPM19-FJ6-A0Z4B3*


* NOTES LED COLOR & VDC

R	RED
G	GREEN
B	BLUE
Y	YELLOW
W	WHITE
BLANK	CLEAR

Dimensions (mm):

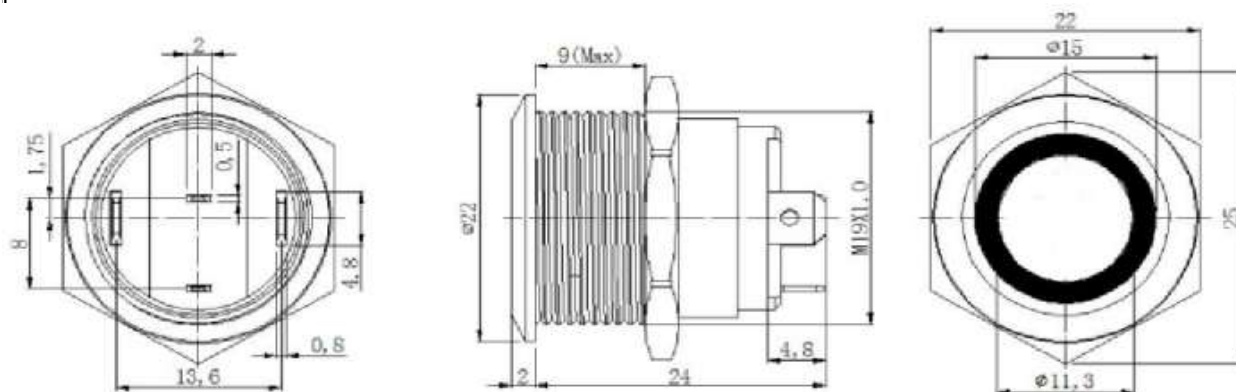

CONNECTION DIAGRAM:

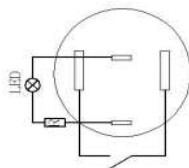

PANEL HOLE:

