



Mallory Sonalert Products, Inc.

Part #: **FPM19-FW6-A0Z4G12**

Sales Outline Drawing

Revision: **A**

Specifications:

May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.

Panel Hole (mm)	19 mm
Switch Rated Voltage (VDC)	12
Switch Rated Current (mA) DC	50
LED Rated Voltage (VDC)	10.8-13.2
LED Rated Current (mA)	≤20
Button Color	Green
Switch Function	OFF-ON
Circuit	SPST 1NO
Storage & Operating Temperature	-25 °C to +85 °C
Ingress Protection Rating	IP67
Shock Resistance	IK08
Material	PC Plastic, PA66+GF20%, Aluminum Alloy
Termination Type	Wires
Wire Specification	7.3" (185 mm) PVC AWG18

RoHS Compliant


Part Number:

FPM19-FW6-A0Z4G12*


* NOTES LED COLOR & VDC

R	RED
G	GREEN
B	BLUE
Y	YELLOW
W	WHITE
BLANK	CLEAR

Dimensions (mm):

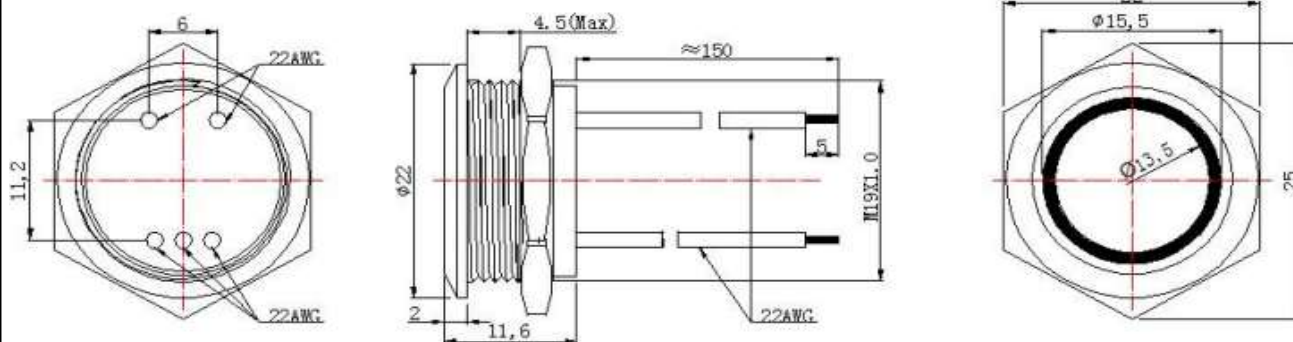

CONNECTION DIAGRAM:

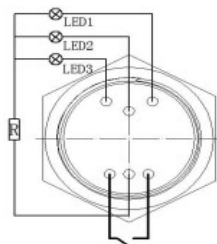

PANEL HOLE:

