



**Mallory Sonalert Products, Inc.**

Part #: **FPM22-FJ6-A0Z4B12**

## Sales Outline Drawing

Revision: **A**

### Specifications:

May not be suitable for all Medical and Aerospace applications.  
Contact Mallory Sonalert to discuss your application.

|                                  |                                        |
|----------------------------------|----------------------------------------|
| Panel Hole (mm)                  | 22 mm                                  |
| Switch Rated Voltage (VDC / VAC) | 36 / 250                               |
| Switch Rated Current (A) DC / AC | 20 / 20                                |
| LED Rated Voltage (VDC)          | 10.8-13.2                              |
| LED Rated Current (mA)           | ≤20                                    |
| Button Color                     | Blue                                   |
| Switch Function                  | OFF-ON                                 |
| Circuit                          | SPST 1NO                               |
| Storage & Operating Temperature  | -25 °C to +85 °C                       |
| Ingress Protection Rating        | IP65                                   |
| Shock Resistance                 | IK09                                   |
| Material                         | PC Plastic, PA66+GF20%, Aluminum Alloy |
| Termination Type                 | Flat Blades-4.8mm                      |

**RoHS Compliant**


### Part Number:

**FPM22-FJ6-A0Z4B12\***


\* NOTES LED COLOR & VDC

|       |        |
|-------|--------|
| R     | RED    |
| G     | GREEN  |
| B     | BLUE   |
| Y     | YELLOW |
| W     | WHITE  |
| BLANK | CLEAR  |

### Dimensions (mm):

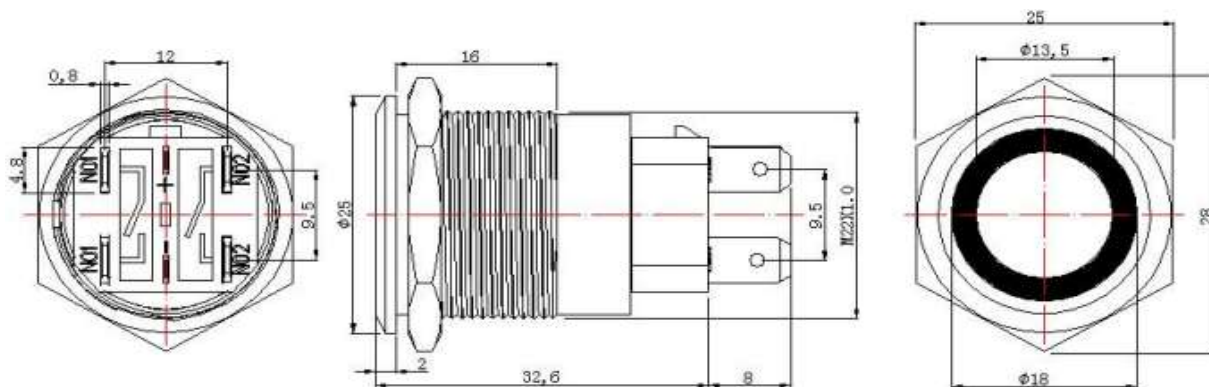

### CONNECTION DIAGRAM:

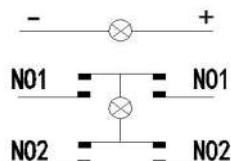

### PANEL HOLE:

