



Mallory Sonalert Products, Inc.

Part #: **FPM22-FW1-A0Z4B12**

Sales Outline Drawing

Revision: **A**

Specifications:

May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.

Panel Hole (mm)	22 mm
Switch Rated Voltage (VDC / VAC)	36 / 250
Switch Rated Current (A) DC / AC	5 / 5
LED Rated Voltage (VDC)	10.8-13.2
LED Rated Current (mA)	≤20
Button Color	Blue
Switch Function	OFF-ON
Circuit	SPST 1NO
Storage & Operating Temperature	-25 °C to +85 °C
Ingress Protection Rating	IP65
Shock Resistance	IK08
Material	PC Plastic, PA66+GF20%, Aluminum Alloy
Termination Type	Wires
Wire Specification	7.3" (185 mm) PVC AWG18

RoHS Compliant


Part Number:

FPM22-FW1-A0Z4B12*


* NOTES LED COLOR & VDC

R	RED
G	GREEN
B	BLUE
Y	YELLOW
W	WHITE
BLANK	CLEAR

Dimensions (mm):

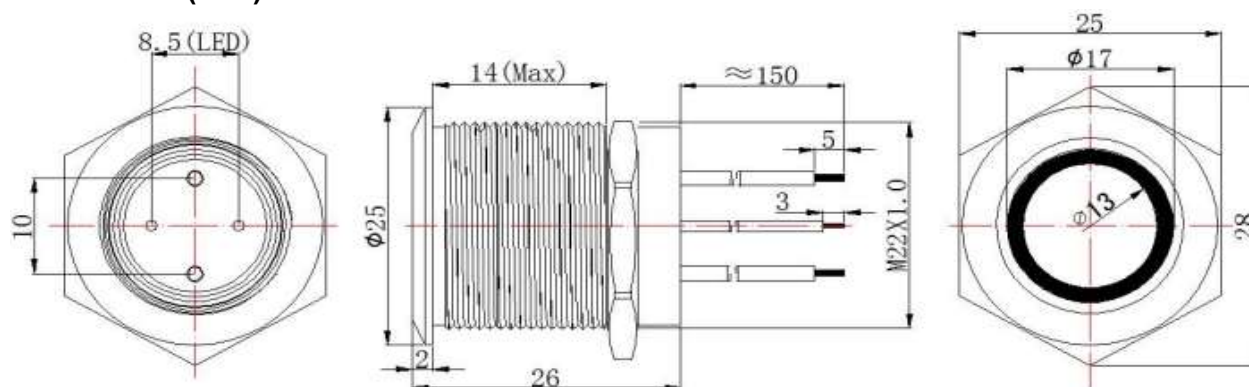

CONNECTION DIAGRAM:

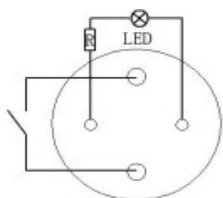

PANEL HOLE:

