



Mallory Sonalert Products, Inc.

Part #: **FPPQ19-FW1-C3-S0M4B24**

Sales Outline Drawing

Revision: **A**

Specifications:

May not be suitable for all Medical and Aerospace applications.

Contact Mallory Sonalert to discuss your application.

Panel Hole (mm)	19 mm
Switch Rated Voltage (VDC / VAC)	36 / 250
Switch Rated Current (A) DC / AC	5 / 5
LED Rated Voltage (VDC)	21.6-26.4
LED Rated Current (mA)	≤20
Button Color	Blue
Switch Function	ON-MOM
Circuit	SPST 1NO
Storage & Operating Temperature	-25 °C to +85 °C
Ingress Protection Rating	IP65
Shock Resistance	IK08
Material	PC Plastic, PA66+GF20%, Stainless
Termination Type	Wires
Wire Specification	7.3" (185 mm) PVC AWG18

RoHS Compliant


Part Number:

FPPQ19-FW1-C3-S0M4B24*


* NOTES LED COLOR & VDC

R	RED
G	GREEN
B	BLUE
Y	YELLOW
W	WHITE
BLANK	CLEAR

Dimensions (mm):

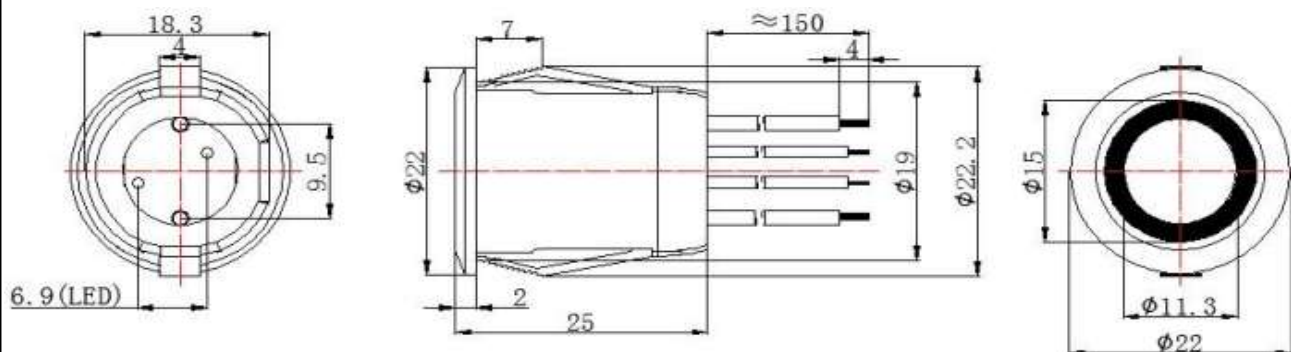

CONNECTION DIAGRAM:

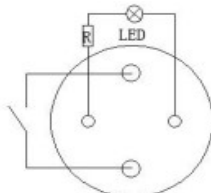

PANEL HOLE:

