



**Mallory Sonalert Products, Inc.**

Part #: **FPPQ19-FW1-C3-S0M4G12**

## Sales Outline Drawing

Revision: **A**

### Specifications:

May not be suitable for all Medical and Aerospace applications.

Contact Mallory Sonalert to discuss your application.

|                                  |                                   |
|----------------------------------|-----------------------------------|
| Panel Hole (mm)                  | 19 mm                             |
| Switch Rated Voltage (VDC / VAC) | 36 / 250                          |
| Switch Rated Current (A) DC / AC | 5 / 5                             |
| LED Rated Voltage (VDC)          | 10.8-13.2                         |
| LED Rated Current (mA)           | ≤20                               |
| Button Color                     | Green                             |
| Switch Function                  | ON-MOM                            |
| Circuit                          | SPST 1NO                          |
| Storage & Operating Temperature  | -25 °C to +85 °C                  |
| Ingress Protection Rating        | IP65                              |
| Shock Resistance                 | IK08                              |
| Material                         | PC Plastic, PA66+GF20%, Stainless |
| Termination Type                 | Wires                             |
| Wire Specification               | 7.3" (185 mm) PVC AWG18           |

**RoHS Compliant**


### Part Number:

**FPPQ19-FW1-C3-S0M4G12\***


\* NOTES LED COLOR & VDC

|       |        |
|-------|--------|
| R     | RED    |
| G     | GREEN  |
| B     | BLUE   |
| Y     | YELLOW |
| W     | WHITE  |
| BLANK | CLEAR  |

### Dimensions (mm):

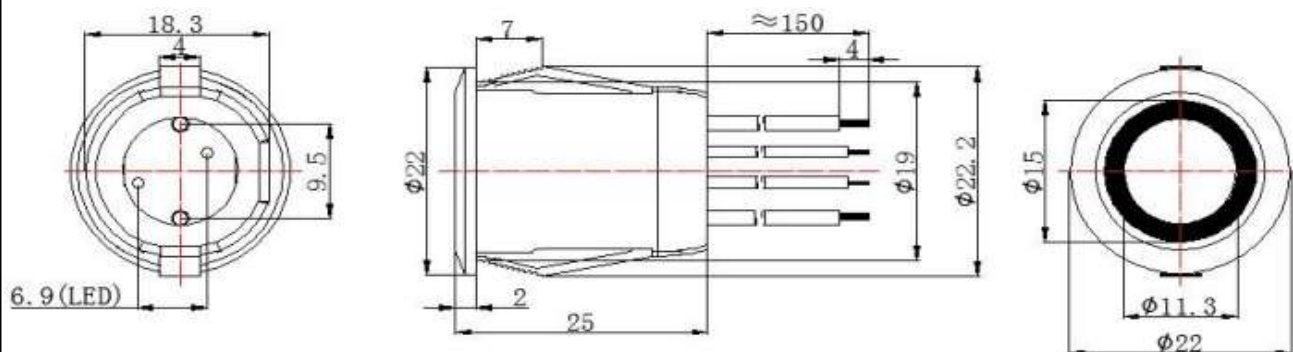

### CONNECTION DIAGRAM:

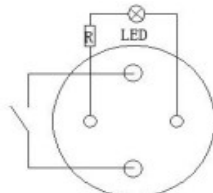

### PANEL HOLE:

